

POTENTIAL TERMINAL BLOCK GRAY GRAY YE BL


Potential terminal block  
gray/gray/yellow/blue

[Link to Product](#)

Illustration



Product may differ from Image

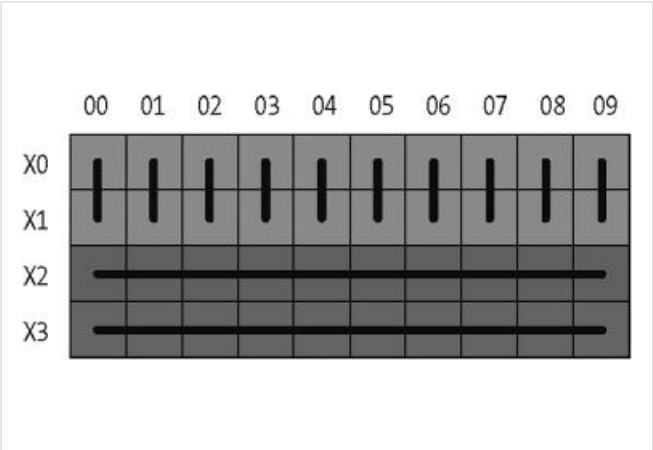

| Commercial data                |                                |
|--------------------------------|--------------------------------|
| ECLASS-6.0                     | 27141106                       |
| ECLASS-6.1                     | 27141106                       |
| ECLASS-7.0                     | 27141106                       |
| ECLASS-8.0                     | 27141106                       |
| ECLASS-9.0                     | 27141106                       |
| ECLASS-10.1                    | 27141106                       |
| ECLASS-11.1                    | 27141106                       |
| ECLASS-12.0                    | 27141106                       |
| ETIM-5.0                       | EC001283                       |
| customs tariff number          | 85369010                       |
| GTIN                           | 4048879049450                  |
| Packaging unit                 | 1                              |
| Electrical data   Supply       |                                |
| Operating voltage AC max.      | 30 V                           |
| Operating voltage DC max.      | 30 V                           |
| Total current max.             | 10 A                           |
| Installation                   |                                |
| Connection cross section max.  | 2,5 mm²                        |
| AWG number min.                | 28                             |
| AWG number max.                | 14                             |
| Installation   Connection      |                                |
| Connection                     | Spring clamp plug-in terminals |
| Device protection   Electrical |                                |

Degree of protection (EN IEC 60529) IP20

**Mechanical data | Mounting data**

|        |         |
|--------|---------|
| Height | 70 mm   |
| Width  | 56 mm   |
| Depth  | 32,5 mm |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | 0 °C   |
| Operating temperature max. | 55 °C  |
| Storage temperature min.   | -40 °C |
| Storage temperature max.   | 85 °C  |