

TREE 6TX ECO - UNMANAGED SWITCH - 6 PORTS


6 port unmanaged switch
Connection cables are in the online shop under "Connection Technology".

Link to Product

Illustration



Product may differ from Image

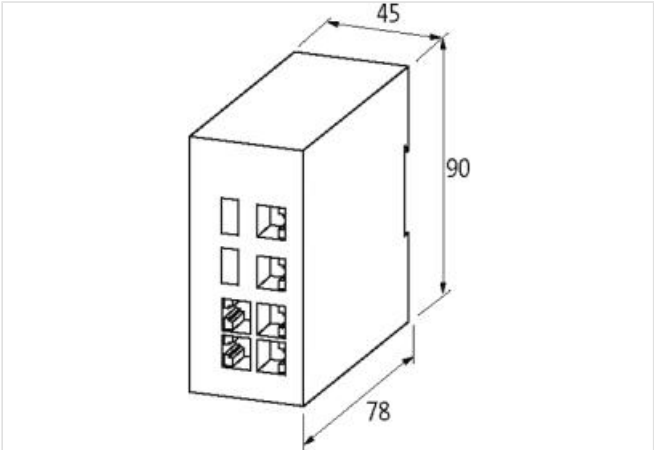

Commercial data	
ECLASS-6.0	19170106
ECLASS-7.0	19170106
ECLASS-8.0	19170106
ECLASS-9.0	19170106
ETIM-5.0	EC000734
customs tariff number	85176200
GTIN	4048879329569
Packaging unit	1
Electrical data Supply	
Operating voltage DC min.	9 V
Operating voltage DC max.	30 V
Industrial communication	
Data transmission rate max.	100 MBit/s
Industrial communication Ethernet functionality	
Auto-crossover	yes
Auto-negotiation	yes
duplex	Full duplex
Switch type	unmanaged
VLAN unmanaged (IEEE 802.1Q)	yes
Diagnostics	
Alarm contact	no
Diagnostic	No voltage

LED display

Ethernet connection/data traffic

Installation | Connection

Number ports	6
--------------	---

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP20
-------------------------------------	------

Mechanical data | Material data

Color housing	black
---------------	-------

Material housing	Plastic
------------------	---------

Mechanical data | Mounting data

Mounting method	geschnappt
-----------------	------------

Suitable for mounting type	Mounting rail TH35, (EN 60715)
----------------------------	--------------------------------

Height	90 mm
--------	-------

Width	45,2 mm
-------	---------

Depth	78 mm
-------	-------

Environmental characteristics | Climatic

Operating temperature min.	0 °C
----------------------------	------

Operating temperature max.	60 °C
----------------------------	-------

Storage temperature min.	-10 °C
--------------------------	--------

Storage temperature max.	70 °C
--------------------------	-------