






# MSDD pass-through USB 3.0 form A, 1.5 m cable, design silver

Pass-through

1 × USB 3.0 (female/male/1.5 m cable) form A

## Link to Product

### Illustration

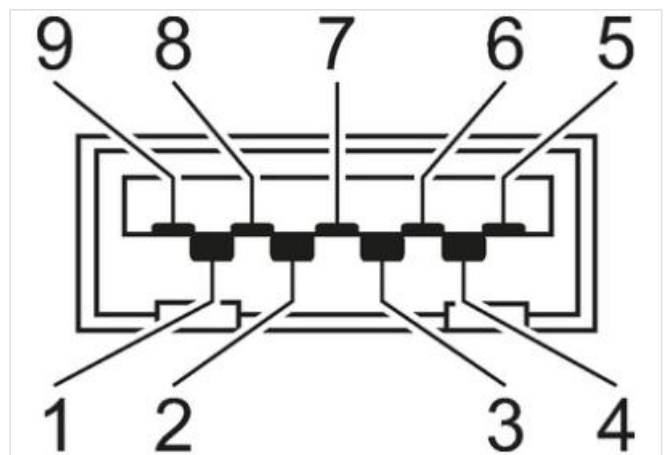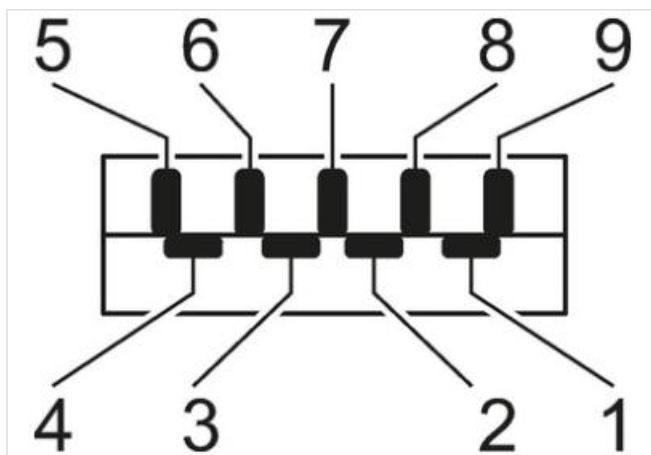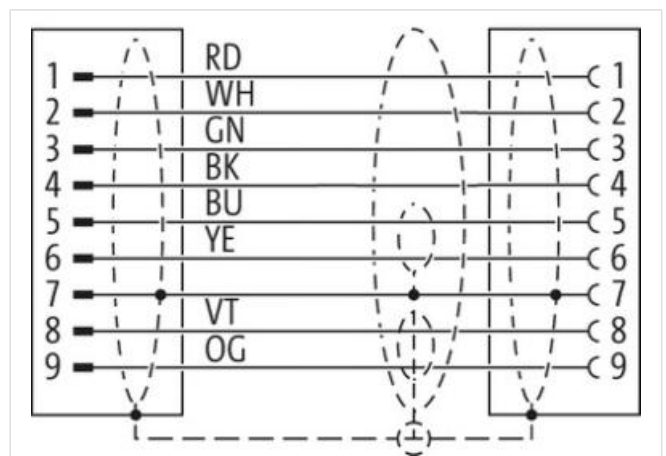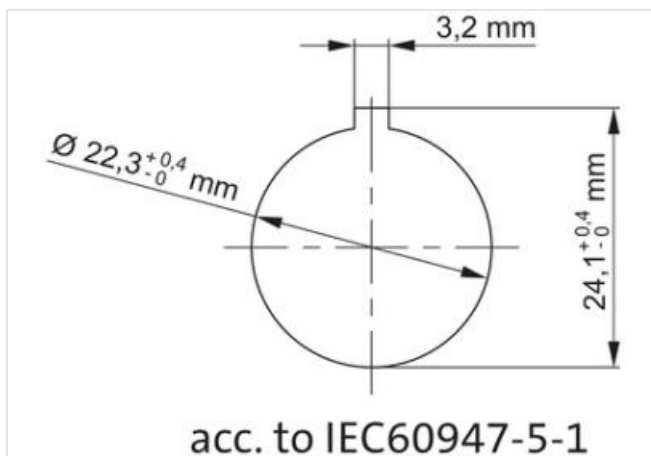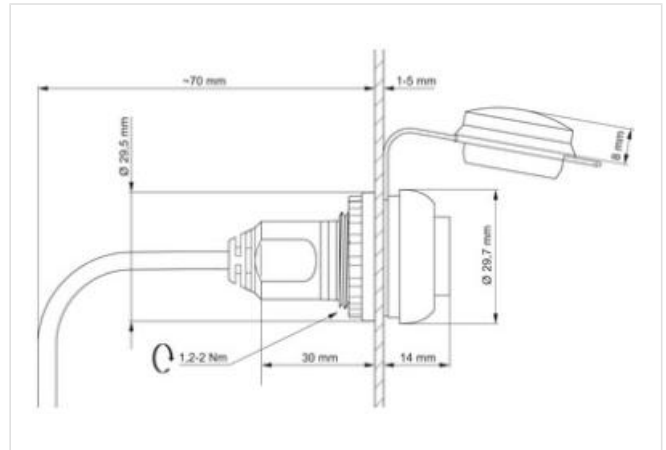

Product may differ from Image



#### Commercial data

|                       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27143423      |
| ECLASS-6.1            | 27143419      |
| ECLASS-7.0            | 27440515      |
| ECLASS-8.0            | 27440515      |
| ECLASS-9.0            | 27440515      |
| ECLASS-10.1           | 27440515      |
| ECLASS-11.1           | 27440515      |
| ECLASS-12.0           | 27440515      |
| ETIM-5.0              | EC002625      |
| customs tariff number | 85444290      |
| GTIN                  | 4048879433419 |
| Packaging unit        | 1             |

#### Electrical data | Supply

|                        |        |
|------------------------|--------|
| Operating voltage AC   | 5 V    |
| Operating voltage DC   | 5 V    |
| Operating current max. | 900 mA |

#### Industrial communication

|                   |     |
|-------------------|-----|
| USB specification | 3.0 |
|-------------------|-----|

#### Device protection

|          |     |
|----------|-----|
| Shielded | yes |
|----------|-----|

#### Device protection | Electrical

|                                        |                           |
|----------------------------------------|---------------------------|
| Degree of protection (EN IEC 60529)    | IP20, IP65                |
| Protection NEMA                        | 2, 3R, 4, 12, 13, 4x      |
| Additional condition protection degree | inserted, in closed state |

#### Device protection | Mechanical

|                      |      |
|----------------------|------|
| Mechanical endurance | 1500 |
|----------------------|------|

#### Mechanical data | Mounting data

|                 |         |
|-----------------|---------|
| Diameter cutout | 22,5 mm |
| Diameter        | 29,5 mm |
| Mounting depth  | 70 mm   |
| Depth           | 30 mm   |

#### Approvals

|        |     |
|--------|-----|
| UL 50E | yes |
|--------|-----|