



SV-2 X SUB D 37 -KL. FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Female connector
37-pole
Screw terminals

[Link to Product](#)

Illustration

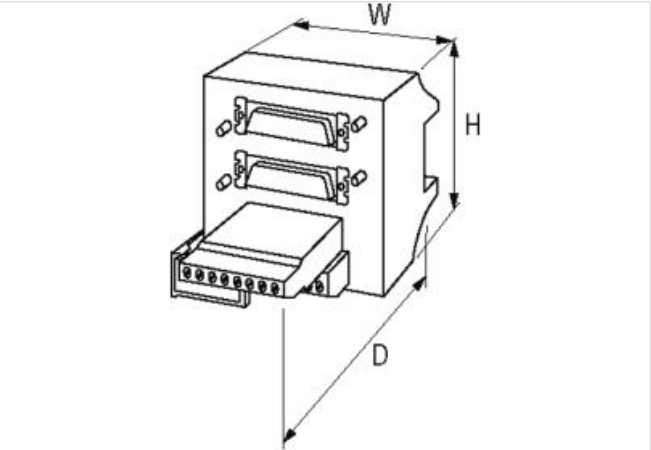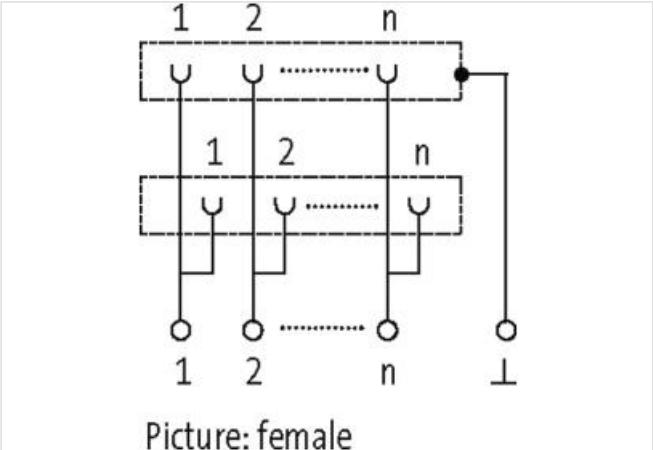

Product may differ from Image

Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
customs tariff number	85366990
GTIN	4048879026192

Packaging unit 1

Electrical data | Supply

Operating voltage AC 125 V

Operating voltage DC 150 V

Operating current max. 2 A

Device protection | Electrical

Overvoltage category (EN 60664-1) I

Mechanical data | Mounting data

Mounting method geschnappt

Suitable for mounting type mounting rail, (EN 60715)

Height 86 mm

Width 90 mm

Depth 78 mm

Looking techniques Standard UNC 4-40 screw thread bolt (EN 60807)

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 70 °C