

POWER DISTRIBUTOR CUBE 67

4x M12, 6-pole


Power distributor (4x M12)
System accessories
Protection IP67
Connection cables are in the online shop under "Connection Technology".
Housing fully potted.

Link to Product

Illustration



Product may differ from Image

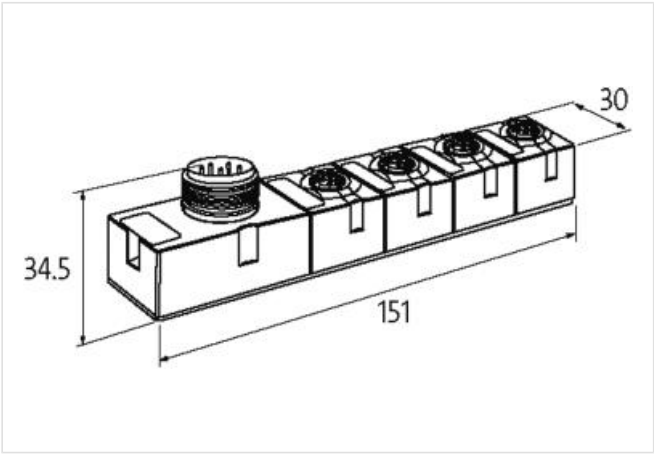

Commercial data	
ECLASS-6.0	27242690
ECLASS-6.1	27242611
ECLASS-7.0	27242611
ECLASS-8.0	27242611
ECLASS-9.0	27242611
ECLASS-10.1	27242611
ECLASS-11.1	27242611
ECLASS-12.0	27242611
ETIM-5.0	EC001583
customs tariff number	85389099
GTIN	4048879047852
Packaging unit	1
Electrical data Supply	
Operating voltage DC	24 V
Electrical data Input	
Input current max.	9 A
Electrical data Output	
Max. current output per port	4 A
Diagnostics	

Diagnostic	No voltage
Short circuit diagnosis	yes
Overload diagnosis	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Mechanical data Mounting data	
Suitable for mounting type	2-hole screw mounting
Height	150 mm
Width	30 mm
Depth	34,5 mm
Environmental characteristics Climatic	
Operating temperature min.	0 °C
Operating temperature max.	55 °C
Storage temperature min.	-20 °C
Storage temperature max.	75 °C
Conformity	
Product standard	EN 61131-2
Connection type 2	
Connection type 1	Bus Out
Connection type 2	Power In (UA 0) (UA 1)
Family construction form	M12
Gender	female
Color contact carrier	black
Coding	A
No. of poles	6
PIN 1	24 V DC
PIN 2	n.c.
PIN 3	0 V
PIN 4	n.c.
PIN 5	n.c.
PIN 6	0 V
Family construction form	7/8"
Gender	male
Color contact carrier	black
No. of poles	5
PIN 1	0 V
PIN 2	0 V
PIN 3	PE
PIN 4	n.c.
PIN 5	24 V DC