



ASSEMBLY MODULE MP 16

Mounting rail / screw-type terminal

16 pairs of solder pins  
screw terminals connected to solder pin pairs

Link to Product

Illustration

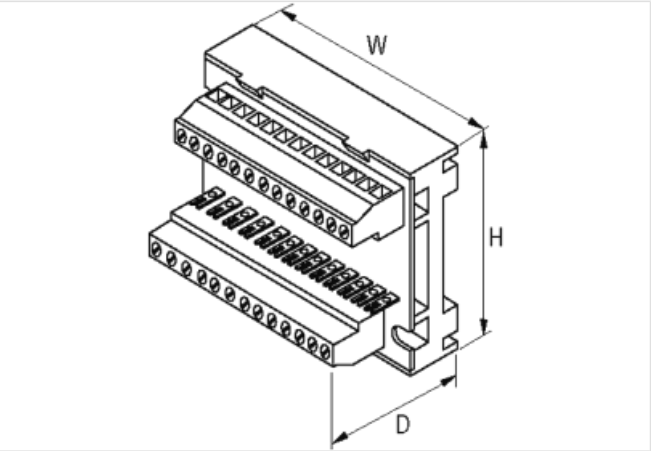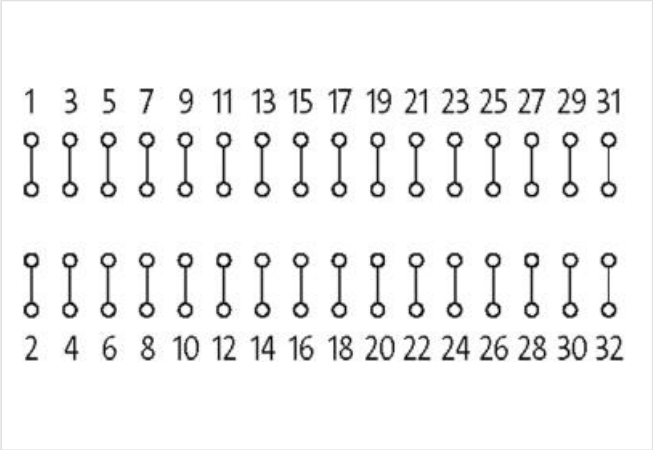

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27260710 |
| ECLASS-6.1      | 27141149 |
| ECLASS-7.0      | 27141149 |
| ECLASS-8.0      | 27141149 |
| ECLASS-9.0      | 27141149 |
| ECLASS-10.1     | 27141149 |
| ECLASS-11.1     | 27141149 |
| ECLASS-12.0     | 27141149 |

|                                                 |                                     |
|-------------------------------------------------|-------------------------------------|
| ETIM-5.0                                        | EC002780                            |
| customs tariff number                           | 85369010                            |
| GTIN                                            | 4048879042246                       |
| Packaging unit                                  | 1                                   |
| <b>Electrical data   Supply</b>                 |                                     |
| Operating voltage AC                            | 50 V                                |
| Operating voltage DC                            | 50 V                                |
| Operating current max.                          | 5 A                                 |
| <b>Installation</b>                             |                                     |
| Connection cross section max.                   | 4 mm <sup>2</sup>                   |
| <b>Installation   Connection</b>                |                                     |
| Connection                                      | Screw terminals SK                  |
| Connection information                          | Lötstützpunktpaare (Raster 5 mm)    |
| <b>Device protection   Media</b>                |                                     |
| Flame resistance                                | flame retardant                     |
| <b>Mechanical data   Material data</b>          |                                     |
| Housing properties                              | open design                         |
| Material housing                                | Plastic                             |
| <b>Mechanical data   Mounting data</b>          |                                     |
| Distance of solder pins                         | 24 mm                               |
| Mounting method                                 | screwed, geschnappt                 |
| Suitable for mounting type                      | Mounting rail TH35, G32, (EN 60715) |
| Height                                          | 63 mm                               |
| Width                                           | 90 mm                               |
| Depth                                           | 36 mm                               |
| <b>Environmental characteristics   Climatic</b> |                                     |
| Operating temperature min.                      | -20 °C                              |
| Operating temperature max.                      | 60 °C                               |