

EUROCARD HOLDER

SKP 48/1 F

Screw terminals

48-pole F (EN 60603)

Row z, b, d

250 V AC



With the vertical snap adapter SASA 135 Art.-No. 63900 the holder can be mounted at right-angles on the rail.

The D2 size is for a card without a front plate.

To insert the card first press down the 2 yellow buttons. Then slide the Eurocard into the guide slots pushing until fully engaged. The card is now locked into position. It can be removed by pressing down on the 2 yellow buttons.

[Link to Product](#)

Illustration

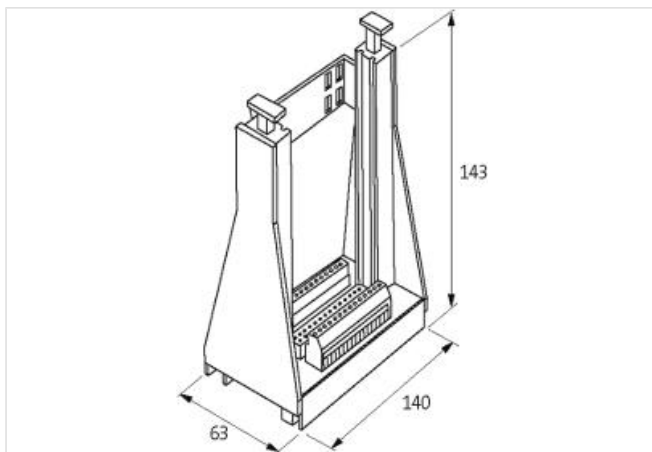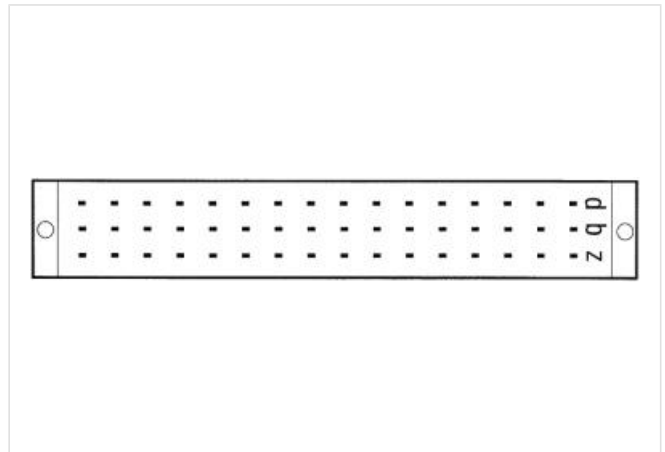

Product may differ from Image



Commercial data

ECLASS-6.0	27260710
ECLASS-6.1	27260704

ECLASS-7.0	27440402
ECLASS-8.0	27440402
ECLASS-9.0	27440402
ECLASS-10.1	27440402
ECLASS-11.1	27460201
ECLASS-12.0	27460201
ETIM-5.0	EC002780
customs tariff number	85366990
GTIN	4048879042154
Packaging unit	1
Electrical data Supply	
Operating voltage AC	250 V
Operating current max.	4 A
Installation	
Connection cross-section solid max.	4 mm ²
Installation Pin assignment	
No. of poles	48
Device protection Electrical	
Overvoltage category (EN 60664-1)	I
Device protection Media	
Flame resistance	flame retardant
Mechanical data	
Type of socket connector	F (EN 60603)
Mechanical data Material data	
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	screwed, geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	137 mm
Width	63 mm
Depth	170 mm