

MSVD POWER SOCKET NEMA

Mounting rail

USA (2× NEMA 5-20)

Screw terminals


Each socket can be loaded with 20 A, however, the total load of both sockets must be below 30 A.

Link to Product

Illustration



Product may differ from Image

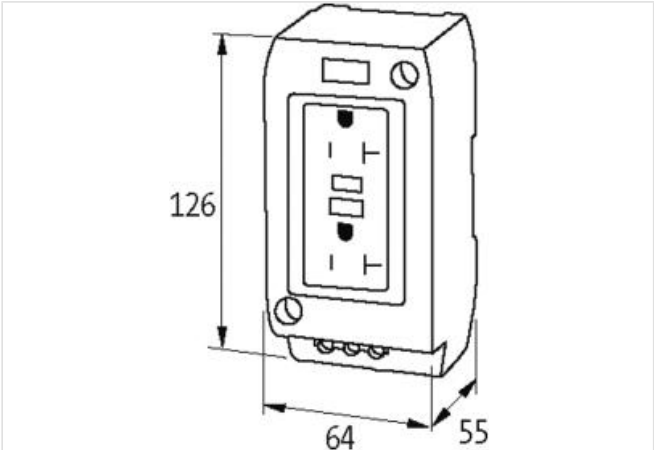

Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879041362
Packaging unit	1
Electrical data Supply	
Operating voltage AC	125 V
Operating current max.	20 A
Installation	
Connection cross section max.	6 mm²
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	126 mm
Width	64 mm
Depth	55 mm