



LED-INDICATOR BLUE

LED 3mm - 24V DC - IP40

(blue)  
24 V DC

Link to Product

Illustration

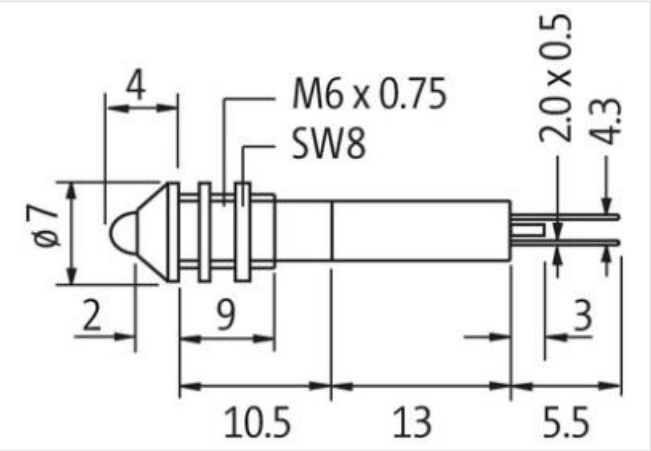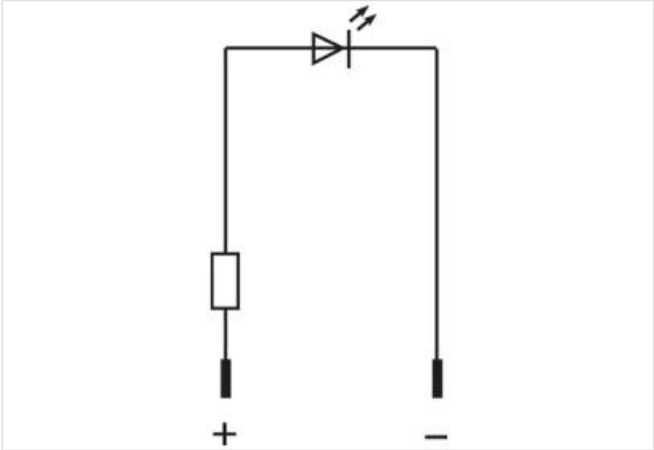

Product may differ from Image

| Commercial data       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27261590      |
| ECLASS-6.1            | 27261501      |
| ECLASS-7.0            | 27261501      |
| ECLASS-8.0            | 27261501      |
| ECLASS-9.0            | 27261501      |
| ECLASS-10.1           | 27261501      |
| ECLASS-11.1           | 27261501      |
| ECLASS-12.0           | 27261501      |
| ETIM-5.0              | EC000272      |
| customs tariff number | 85318070      |
| GTIN                  | 4048879041119 |
| Packaging unit        | 10            |

**Electrical data | Supply**

|                           |        |
|---------------------------|--------|
| Operating voltage DC      | 24 V   |
| Operating voltage DC min. | 20,4 V |
| Operating voltage DC max. | 26,4 V |
| Current consumption max.  | 18 mA  |

**Installation | Connection**

|                        |                   |
|------------------------|-------------------|
| Connection information | Faston 2.0×0.5 mm |
|------------------------|-------------------|

**Mechanical data | Material data**

|                  |               |
|------------------|---------------|
| Coating housing  | chrome-plated |
| Material housing | Brass         |

**Mechanical data | Mounting data**

|        |       |
|--------|-------|
| Height | 7 mm  |
| Width  | 7 mm  |
| Depth  | 33 mm |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -40 °C |
| Operating temperature max. | 70 °C  |