



LED-INDICATOR BLUE

LED 5mm - 24V AC/DC - 15mA - IP67

(blue)  
24 V AC/DC  
Protection IP67

[Link to Product](#)

Illustration

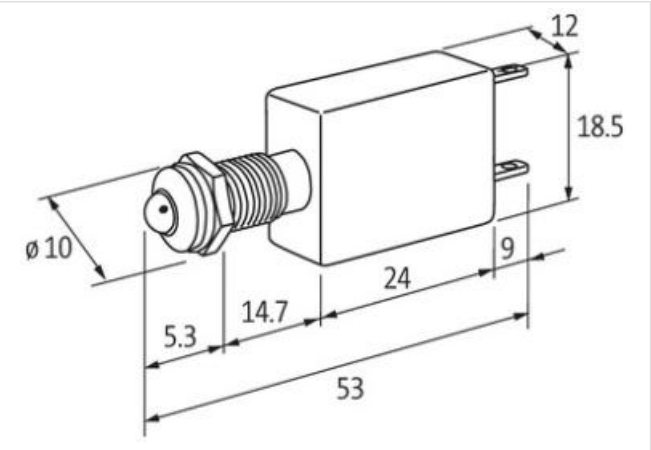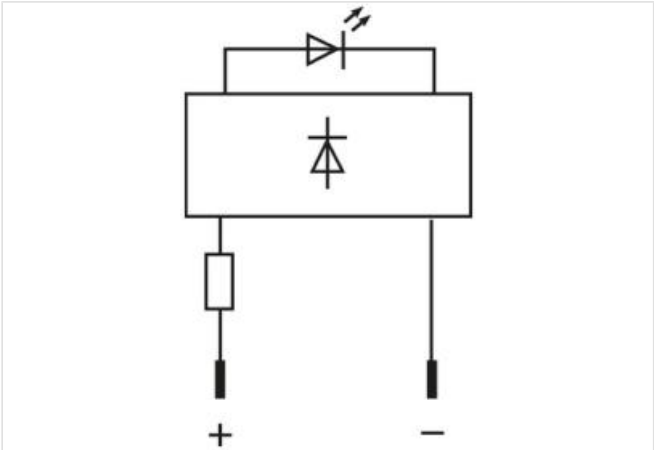

Product may differ from Image

| Commercial data       |               |
|-----------------------|---------------|
| ECLASS-6.0            | 27261590      |
| ECLASS-6.1            | 27261501      |
| ECLASS-7.0            | 27261501      |
| ECLASS-8.0            | 27261501      |
| ECLASS-9.0            | 27261501      |
| ECLASS-10.1           | 27261501      |
| ECLASS-11.1           | 27261501      |
| ECLASS-12.0           | 27261501      |
| ETIM-5.0              | EC000272      |
| customs tariff number | 85318070      |
| GTIN                  | 4048879040686 |

Packaging unit 10

#### Electrical data | Supply

|                           |        |
|---------------------------|--------|
| Operating voltage AC      | 24 V   |
| Operating voltage AC min. | 20,4 V |
| Operating voltage AC max. | 26,4 V |
| Operating voltage DC      | 24 V   |
| Operating voltage DC min. | 20,4 V |
| Operating voltage DC max. | 26,4 V |
| Current consumption min.  | 13 mA  |
| Current consumption max.  | 17 mA  |

#### Installation | Connection

Connection information Faston 2.8x0.8 mm

#### Device protection | Electrical

Degree of protection (EN IEC 60529) IP67

#### Mechanical data

Diameter LED 5 mm

#### Mechanical data | Material data

Color housing gray  
Material housing PVC

#### Mechanical data | Mounting data

Diameter front panel drilling 8 mm  
Height 18,5 mm  
Width 12 mm  
Depth 53 mm

#### Environmental characteristics | Climatic

Operating temperature min. -40 °C  
Operating temperature max. 70 °C