



**MB CAP ULTRA ADD-ON-MODULE**

IN: 0-26,4VDC OUT:0-26,4VDC/3A for max.1A/21S

INPUT: 24 V DC (SELV/PELV)  
OUTPUT: max. 3 A  
12 s (3 A); 36 s (1 A)

[Link to Product](#)

Illustration

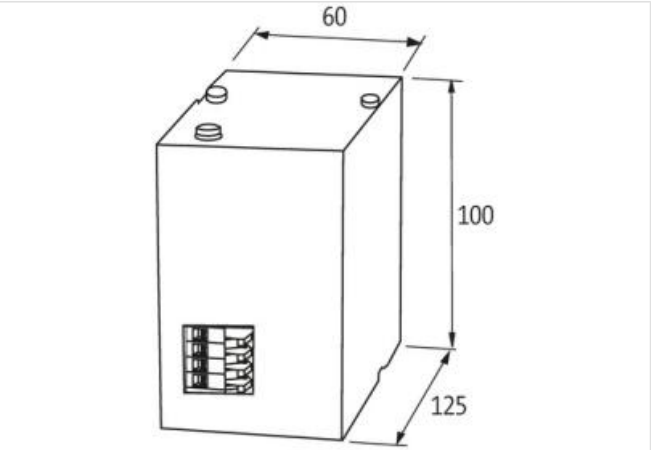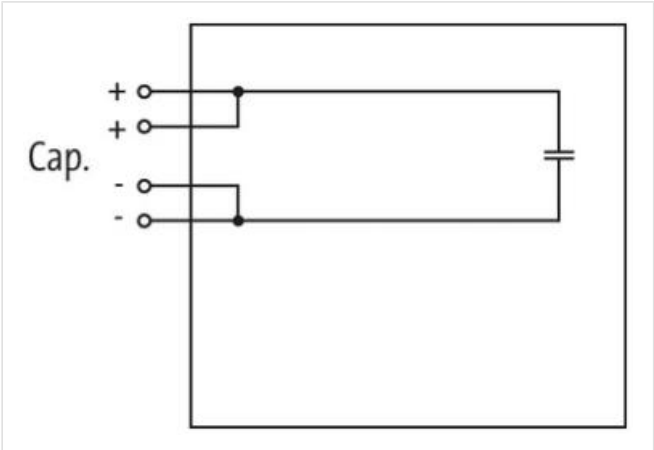

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27049190 |
| ECLASS-6.1      | 27049201 |
| ECLASS-7.0      | 27049201 |
| ECLASS-8.0      | 27049201 |
| ECLASS-9.0      | 27049201 |
| ECLASS-10.1     | 27040692 |

|                                                 |                                |
|-------------------------------------------------|--------------------------------|
| ECLASS-11.1                                     | 27040692                       |
| ECLASS-12.0                                     | 27040692                       |
| ETIM-5.0                                        | EC002584                       |
| customs tariff number                           | 85322900                       |
| GTIN                                            | 4048879079792                  |
| Packaging unit                                  | 1                              |
| <b>Electrical data</b>                          |                                |
| Security level                                  | SELV/PELV                      |
| <b>Electrical data   Input</b>                  |                                |
| Input voltage DC min.                           | 0 V                            |
| Input voltage DC max.                           | 26,4 V                         |
| Current input AC                                | 3 A                            |
| Efficiency                                      | 90 %                           |
| <b>Electrical data   Output</b>                 |                                |
| Output voltage DC min.                          | 0 V                            |
| Output voltage DC max.                          | 26,4 V                         |
| Output voltage adjustable                       | yes                            |
| Output current max.                             | 3 A                            |
| <b>Mechanical data   Mounting data</b>          |                                |
| Mounting method                                 | geschnappt                     |
| Suitable for mounting type                      | Mounting rail TH35, (EN 60715) |
| <b>Environmental characteristics   Climatic</b> |                                |
| Operating temperature min.                      | -20 °C                         |
| Operating temperature max.                      | 60 °C                          |
| Storage temperature min.                        | -20 °C                         |
| Storage temperature max.                        | 60 °C                          |
| <b>Conformity</b>                               |                                |
| Product standard                                | EN 60950, EN 50178             |