



MIRO 6,2 Valvecontrol 24VDC/1ms

In:24VDC OUT:24VDC/1,5A

Switching accelerator: 1 ms/24 V DC
Screw terminals

[Link to Product](#)

Illustration

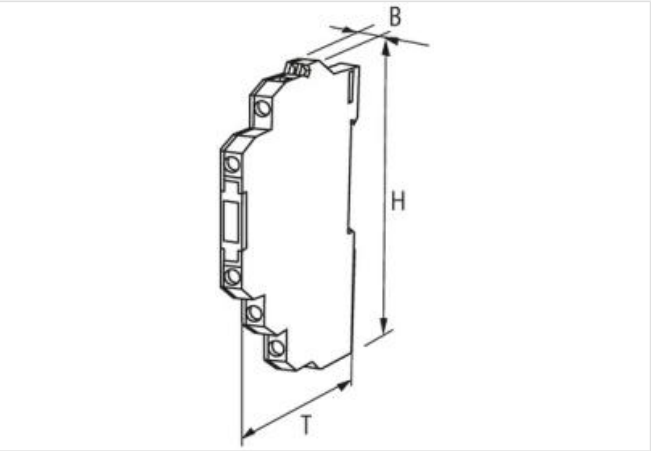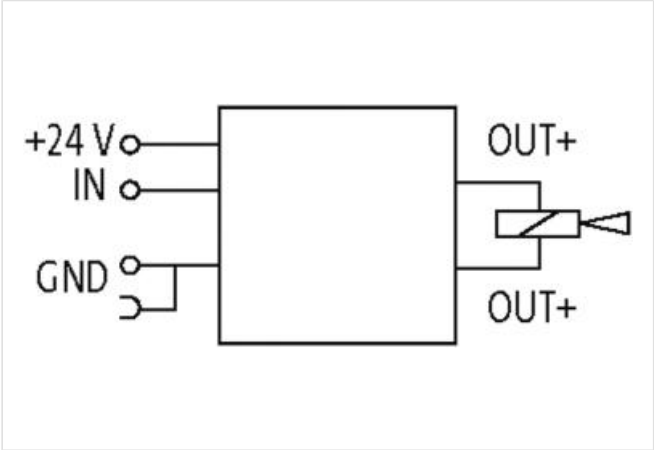

Product may differ from Image



| Electrical data Input | |
|--------------------------|--------|
| Input voltage DC | 24 V |
| Input voltage DC min. | 18 V |
| Input voltage DC max. | 30 V |
| Input current | 13 mA |
| Electrical data Output | |
| Output current | 1,5 A |
| Output current max. | 0,38 A |

| | |
|-----------------------------|-------|
| Duration surge current max. | 1 ms |
| Switching frequency max. | 20 Hz |
| Surge current max. | 1,5 A |

Mechanical data | Mounting data

| | |
|----------------------------|---------------------------|
| Mounting method | geschnappt |
| Suitable for mounting type | mounting rail, (EN 60715) |
| Height | 91 mm |
| Width | 6,2 mm |
| Depth | 71 mm |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | 0 °C |
| Operating temperature max. | 55 °C |
| Storage temperature min. | -25 °C |
| Storage temperature max. | 50 °C |

Connection type 4

| | |
|--------------------------|--------------------|
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | black |
| No. of poles | 1 |
| PIN 1 | GD |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | black |
| No. of poles | 1 |
| PIN 1 | In |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | black |
| No. of poles | 1 |
| PIN 1 | O 1 |
| Connection | Screw terminals SK |
| Family construction form | terminal |
| Gender | female |
| Color contact carrier | black |
| No. of poles | 1 |
| PIN 1 | O 2 |

Commercial data

| | |
|-----------------------|---------------|
| customs tariff number | 85437090 |
| GTIN | 4048879571876 |
| Packaging unit | 10 |