
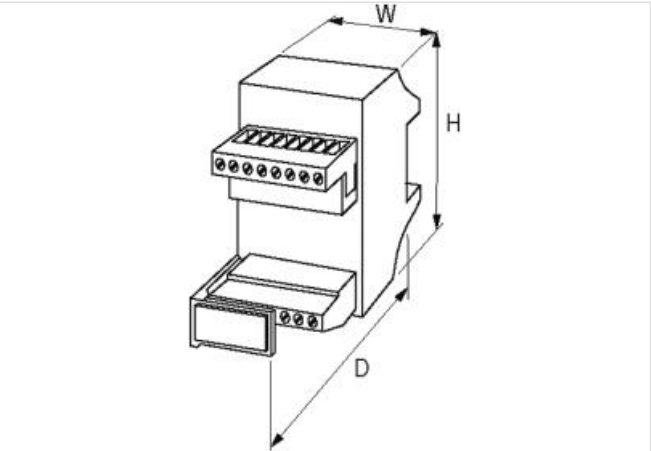


TRANSFER MODULE FOR DIN RAIL MOUNTING

23-pole
for 1× 11- and 1× 12-pole spring clamp terminals
pre-wired to push-in spring clamp terminals

Link to Product

Illustration

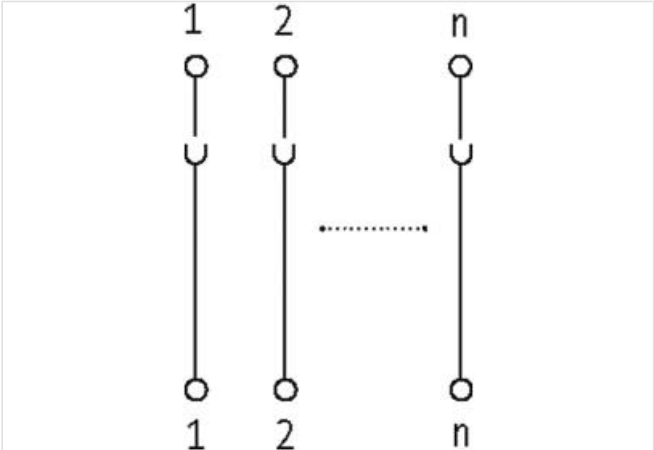

Product may differ from Image



Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152

ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879315692
Packaging unit	1
Electrical data Supply	
Operating voltage DC	24 V
Operating current max.	8 A
Installation	
Connection cross-section solid max.	1 mm ²
Installation Connection	
Connection	Push-In spring clamp terminals
Device protection Electrical	
Overvoltage category (EN 60664-1)	III
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	65 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C