

MSVD POWER SOCKET NEMA WITH LED

Mounting rail


USA (NEMA 5-15)  
Screw terminals  
LED (yellow)

Link to Product

Illustration



Product may differ from Image

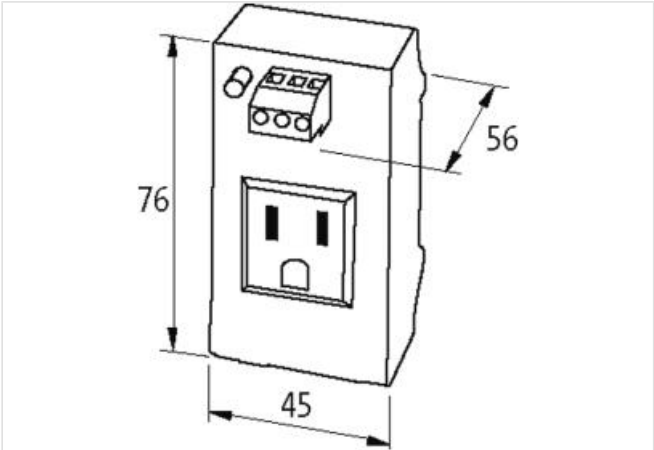

Commercial data	
ECLASS-6.0	27189217
ECLASS-6.1	27142305
ECLASS-7.0	27142305
ECLASS-8.0	27142305
ECLASS-9.0	27142305
ECLASS-10.1	27142305
ECLASS-11.1	27142305
ECLASS-12.0	27142305
ETIM-5.0	EC000020
customs tariff number	85366990
GTIN	4048879039642
Packaging unit	1
Electrical data   Supply	
Operating voltage AC	127 V
Operating current	15 A
Installation	
Connection cross section max.	2,5 mm²
AWG number	14
Installation   Connection	
Connection	Screw terminals SK
Mechanical data   Mounting data	

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	56 mm