



MODLINK MSDD FRAME SINGLE METALIC

Closure Daimler


Frame: plastic PA black  
Lid: plastic, ABS gray  
Closure: Daimler

Link to Product

Illustration

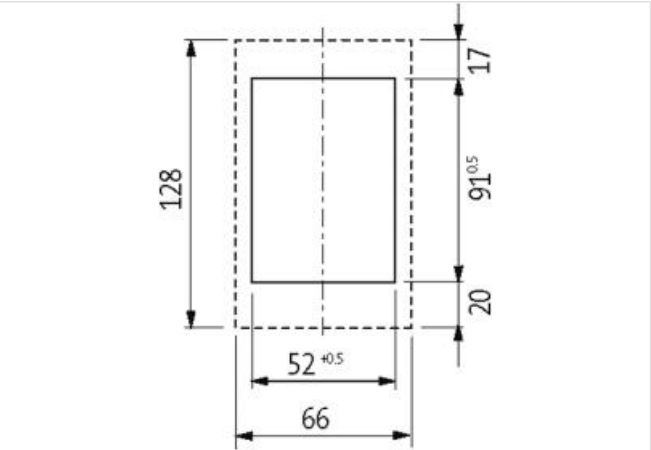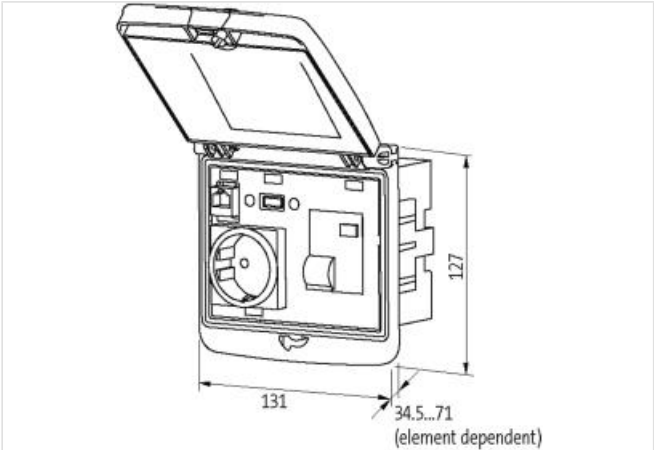

Product may differ from Image

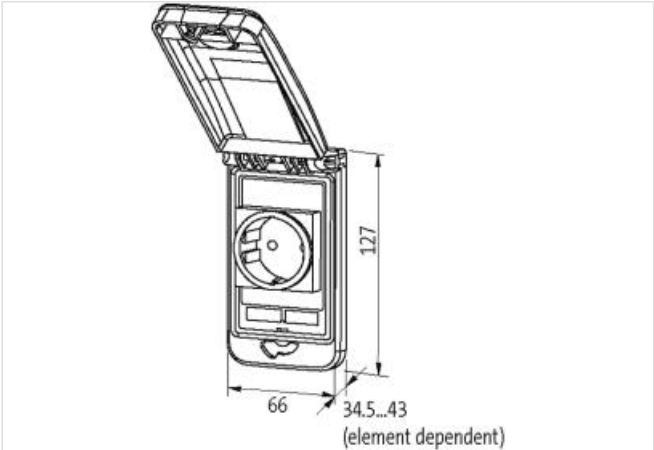

| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27189217 |
| ECLASS-6.1      | 27189260 |
| ECLASS-7.0      | 27189260 |
| ECLASS-8.0      | 27189260 |
| ECLASS-9.0      | 27189260 |
| ECLASS-10.1     | 27182810 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27182810      |
| ECLASS-12.0           | 27182810      |
| ETIM-5.0              | EC002625      |
| customs tariff number | 85389099      |
| GTIN                  | 4048879388030 |
| Packaging unit        | 1             |

**Mechanical data | Mounting data**

|        |        |
|--------|--------|
| Height | 127 mm |
| Width  | 66 mm  |
| Depth  | 43 mm  |

**Frame**

|                                               |          |
|-----------------------------------------------|----------|
| Degree of protection (EN IEC 60529)           | IP65     |
| Operating temperature min.                    | -30 °C   |
| Operating temperature max.                    | 70 °C    |
| Storage temperature min.                      | -30 °C   |
| Storage temperature max.                      | 80 °C    |
| Suitable for installation wall thickness min. | 1 mm     |
| Suitable for installation wall thickness max. | 5 mm     |
| Color cover                                   | metallic |
| Color housing                                 | black    |
| Material lid                                  | ABS      |
| Material housing                              | PA       |