

MODLIGHT70 CONNECTION MODULE 8 POLE M12 BOTTOM EXIT

Product discontinued


Basic + buzzer + flash
with M12 connection
Outlet on the bottom

Link to Product

Illustration



Product may differ from Image

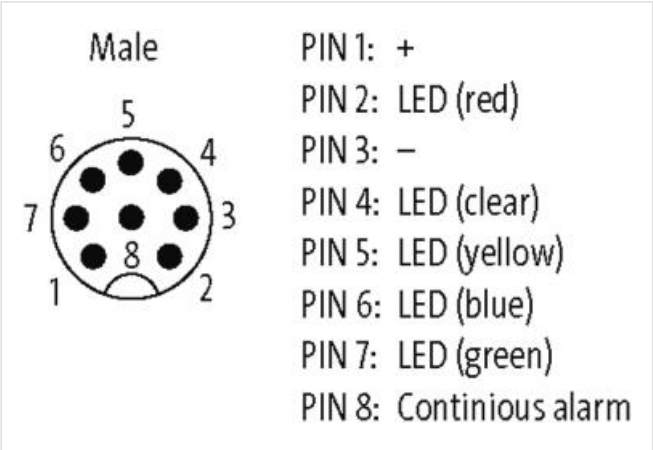

Commercial data	
ECLASS-6.0	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ETIM-5.0	EC001155
customs tariff number	85319000
GTIN	4048879030908
Packaging unit	1
Electrical data Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
Mechanical data Material data	
Color housing	black
Material housing	Plastic
Mechanical data Mounting data	
Height	190 mm

Width	70 mm
Depth	70 mm
Environmental characteristics Climatic	
Operating temperature min.	-30 °C
Operating temperature max.	60 °C
Connection type 1	
Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	+
PIN 2	LED RD
PIN 3	-
PIN 4	LED CL
PIN 5	LED YE
PIN 6	LED BU
PIN 7	LED GN
PIN 8	Continuous tone