

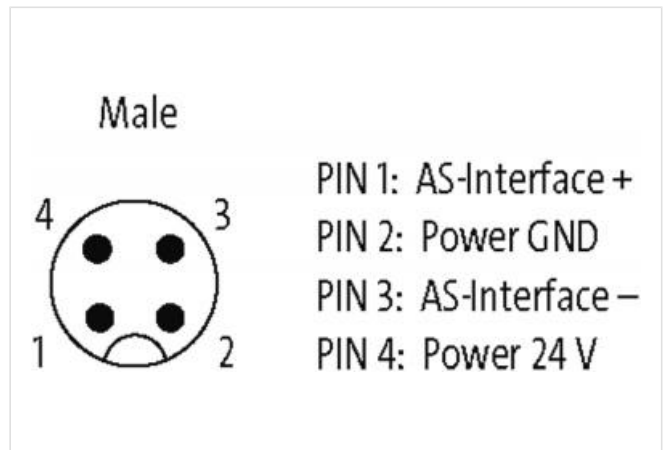
EOL - MODLIGHT70 CONNECTION MODULE 4 POLE M12 BOTTOM EXIT

Product discontinued, no alternative

Basic AB-Slave
4 outputs
with M12 connection
for LED modules and LED flash modules

[Link to Product](#)**Illustration**

Product may differ from Image

**Technical Data**

Bus voltage (AS-Interface)	26.5...31.6 V DC
Total current (AS-Interface)	max. 20 mA
Addressing	via master or M12 connection and programming device
Address range	1...62 (1...31 A or B)
Profile (IO/ID/ID2 code)	S-7.A.7

Output

Number	4
Supply voltage	24 V DC external (18...30.2 V DC) EN 61131-2
Switching current per output	max. 0.5 A (short-circuit and overload protected), suitable for LED flash modules

General data

Protection	IP65 inserted and tightened
Connection	M12 (4-pole)
Housing	Black plastic
Dimensions H×W×D	190×70×70 mm
Temperature range	-30...+60 °C

Commercial data

customs tariff number	85319000
GTIN	4048879030878
Packaging unit	1