

EOL - MODLIGHT70 CONNECTION MODULE 4 POLE M12 BOTTOM EXIT

Product discontinued, no alternative


Basic AB-Slave
5 outputs
with M12 connection
for LED modules and LED flash modules

Link to Product

Illustration



Product may differ from Image

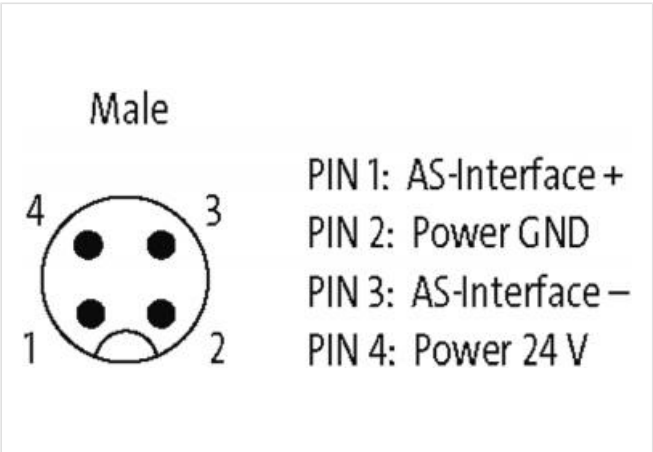

Technical Data

Bus voltage (AS-Interface)	26.5...31.6 V DC
Total current (AS-Interface)	max. 40 mA
Addressing (2 slaves)	via master or M12 connection and programming device, address presetting 31 A/31 B
Address range	1...62 (2 × 1...31 A or B)
Profile (IO/ID/ID2 code)	S-7.A.7

Output

Number	3 - (13-14), (23-24), (33-34), STOP0; 2 - (47-48), (57-58), STOP1
Supply voltage	24 V DC external (18...30.2 V DC) EN 61131-2
Switching current per output	max. 0.5 A (short-circuit and overload protected), suitable for LED flash modules

General data

Protection	IP65 inserted and tightened
Connection	M12 (4-pole)
Housing	Black plastic
Dimensions H×W×D	190×70×70 mm
Temperature range	-30...+60 °C

Commercial data

customs tariff number	85319000
GTIN	4048879030854
Packaging unit	1