

MODLIGHT70 CONNECTION MODULE 8 POLE M12 SIDE EXIT

Product discontinued


Basic  
Outlet on the side  
with M12 connection

Link to Product

Illustration



Product may differ from Image

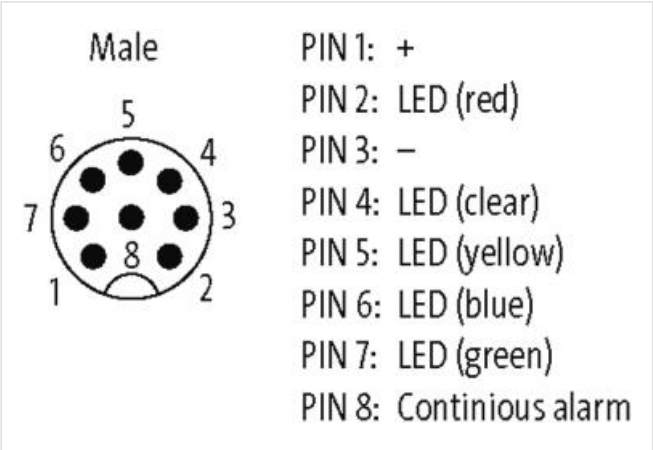

Commercial data	
ECLASS-6.0	27371232
ECLASS-7.0	27371232
ECLASS-8.0	27371232
ECLASS-9.0	27371232
ETIM-5.0	EC001155
customs tariff number	85319000
GTIN	4048879030830
Packaging unit	1
Electrical data   Supply	
Operating voltage DC	24 V
Operating voltage DC min.	21,6 V
Operating voltage DC max.	26,4 V
Device protection   Electrical	
Degree of protection (EN IEC 60529)	IP65
Additional condition protection degree	inserted, locked
Mechanical data   Material data	
Color housing	black
Material housing	Plastic
Mechanical data   Mounting data	
Height	190 mm

Width	70 mm
Depth	70 mm
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-30 °C
Operating temperature max.	60 °C
<b>Connection type 1</b>	
Family construction form	M12
Gender	male
Coding	A
No. of poles	8
PIN 1	+
PIN 2	LED RD
PIN 3	-
PIN 4	LED CL
PIN 5	LED YE
PIN 6	LED BU
PIN 7	LED GN
PIN 8	Continuous tone