

EOL - MODLIGHT70 CONNECTION MODULE 8 POLE M12 SIDE EXIT

Product discontinued


Basic + buzzer + flash  
with M12 connection  
with magnet base

Link to Product

Illustration



Product may differ from Image

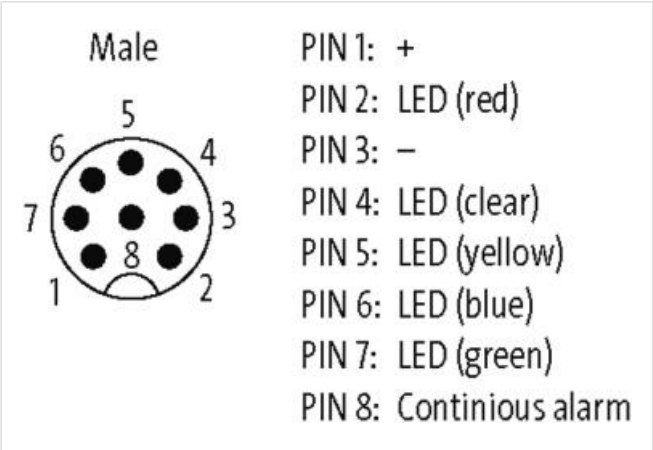

Technical Data	
Operating voltage	24 V DC (21.6...26.4 V DC)
Buzzer (infinitely adjustable)	Continuous and intermittent alarm
Sound pressure level	70 ±5...90 ±5 dB
Blink cycles	60 ±12 per minute
Adhesive force	290 N (depending on surface)
General data	
Protection	IP65 inserted and tightened
Connection	M12 (8-pole)
Housing	Black plastic
Dimensions H×W×D	220.5×70×70 mm
Temperature range	-30...+60 °C
Commercial data	
customs tariff number	85319000
GTIN	4048879030748
Packaging unit	1