

EOL - SIGNAL TOWER MODLIGHT70 EQUIPPED WITH LED MODULES

Product discontinued, no alternative


Basis, buzzer, flash + LED modules + M12 (side) + LED flash (transparent)
red, yellow, green, white-flash

Link to Product

Illustration



Product may differ from Image

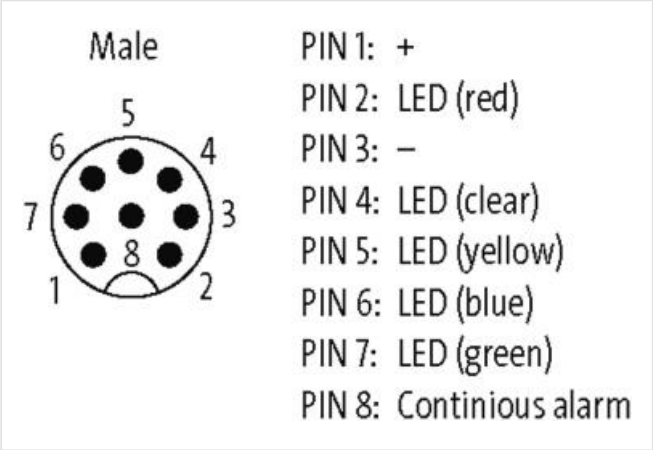

Technical Data	
Operating voltage	24 V DC (21.6...26.4 V DC)
Current consumption	max. 340 ±90 mA
Buzzer (infinitely adjustable)	Continuous and intermittent alarm
Sound pressure level	70 ±5...90 ±5 dB
Blink cycles	60 ±12 per minute
Flash cycles	77 ±10 per minute
Flash	Double flash
General data	
Protection	IP65 inserted and tightened
Connection	M12 (8-pole)
Housing	Black plastic
Dimensions H×W×D	293×70×70 mm
Temperature range	-30...+60 °C
Commercial data	
customs tariff number	85318070
GTIN	4048879292245
Packaging unit	1