

EOL - SIGNAL TOWER MODLIGHT70 EQUIPPED WITH LED MODULES

Product discontinued


Basic, buzzer, flash + LED modules + M12 (side)
green, yellow, red

Link to Product

Illustration



Product may differ from Image

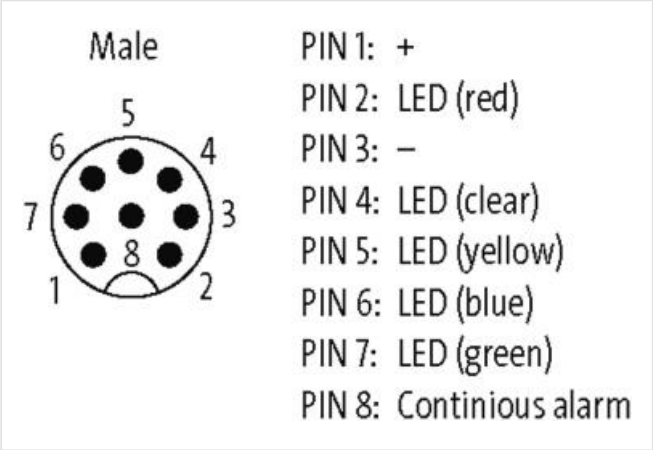

| Technical Data | |
|--------------------------------|-----------------------------------|
| Operating voltage | 24 V DC (21.6...26.4 V DC) |
| Current consumption | max. 62.5 mA |
| Buzzer (infinitely adjustable) | Continuous and intermittent alarm |
| Sound pressure level | 70 ±5...90 ±5 dB |
| Blink cycles | 60 ±12 per minute |
| General data | |
| Protection | IP65 inserted and tightened |
| Connection | M12 (8-pole) |
| Housing | Black plastic |
| Dimensions HxWxD | 293x70x70 mm |
| Temperature range | -30...+60 °C |
| Commercial data | |
| customs tariff number | 85318070 |
| GTIN | 4048879292238 |
| Packaging unit | 1 |