
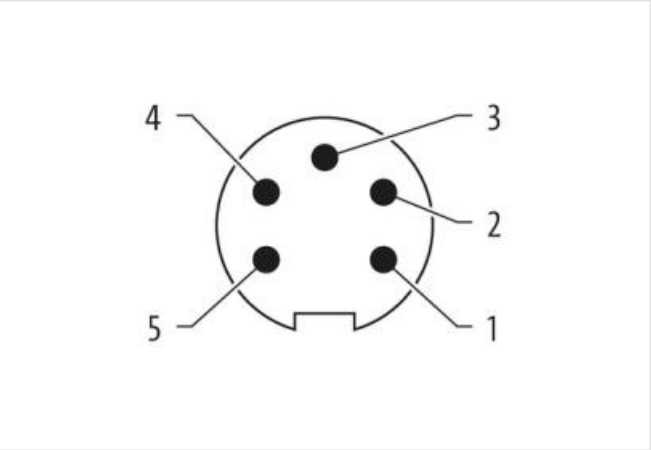


7/8" MALE 0° BUS-FERRULE RESISTOR

Terminating resistor  
Male  
7/8" (5-pole)  
screw fixing  
Plastic housings with good resistance against chemicals and oils.  
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

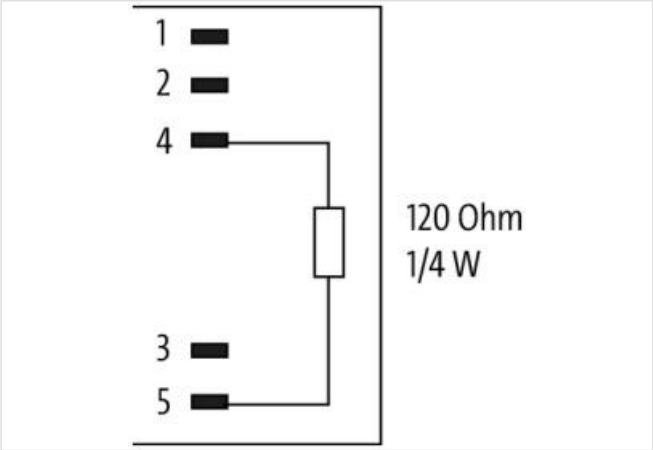

Product may differ from Image



Commercial data	
ECLASS-6.0	27279218
ECLASS-7.0	27279218
ECLASS-8.0	27279218
ECLASS-9.0	27060311
ETIM-5.0	EC001855
customs tariff number	85332900

GTIN	4048879134699
------	---------------

Packaging unit	1
----------------	---

**Electrical data | Supply**

Current operating per contact max.	8 A
------------------------------------	-----

**Device protection | Electrical**

Degree of protection (EN IEC 60529)	IP67
-------------------------------------	------

Additional condition protection degree	inserted, screwed
--	-------------------

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
----------------------------	--------

Operating temperature max.	80 °C
----------------------------	-------