



MICO FUSE 250 FUSE HOLDER 5X20MM 8 CHANNELS

IN: 250V AC/DC OUT: 250V AC/DC / 6A AC/DC

MICO FUSE 250
8 channels
Total current: max. 40 A

[Link to Product](#)

Illustration

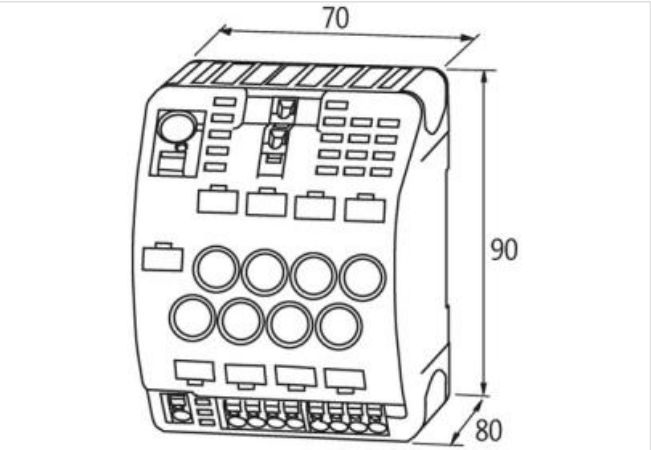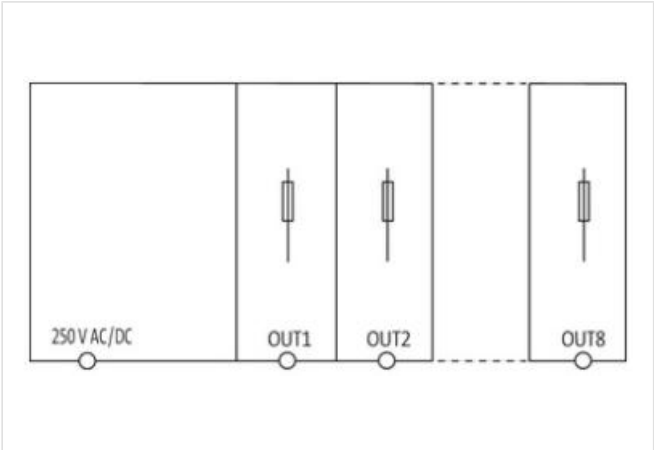

Product may differ from Image



Commercial data	
ECLASS-6.0	27371802
ECLASS-6.1	27142107
ECLASS-7.0	27142121
ECLASS-8.0	27142121
ECLASS-9.0	27142121
ECLASS-10.1	27142121

ECLASS-11.1	27142121
ECLASS-12.0	27142121
ETIM-5.0	EC001440
customs tariff number	85363030
GTIN	4048879335270
Packaging unit	1
Electrical data Supply	
Operating voltage AC max.	250 V
Operating voltage DC max.	250 V
Operating current max.	6 A
Total current max.	40 A
Installation	
Connection cross-section inputs max.	16 mm²
Connection cross-section outputs min.	0,5 mm²
Connection cross-section outputs max.	4 mm²
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	90 mm
Width	70 mm
Depth	80 mm
Environmental characteristics Climatic	
Operating temperature min.	-25 °C
Operating temperature max.	55 °C
Derating from	40 °C
Connection type 3	
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	1
PIN 1	In
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	Out 1
PIN 2	Out 2
PIN 3	Out 3
PIN 4	Out 4
Connection	Spring clamp terminals FK
Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	4
PIN 1	Out 5
PIN 2	Out 6
PIN 3	Out 7
PIN 4	Out 8