

MOTOR SUPPRESSOR

RC, 3x575VAC/45kW

Art.No.: 23103

Weight: 0.154

Country of origin: CZ

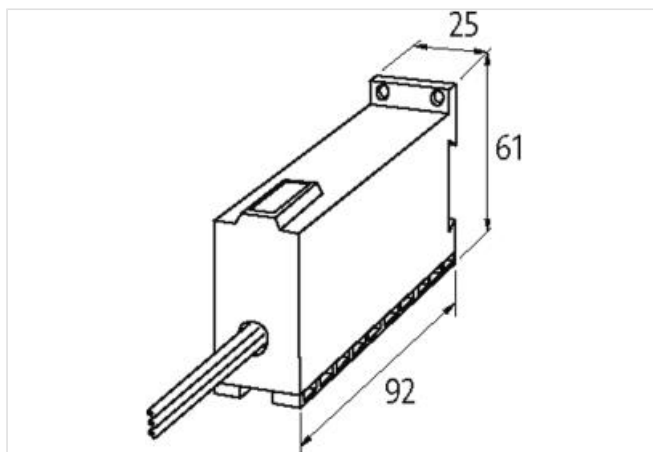
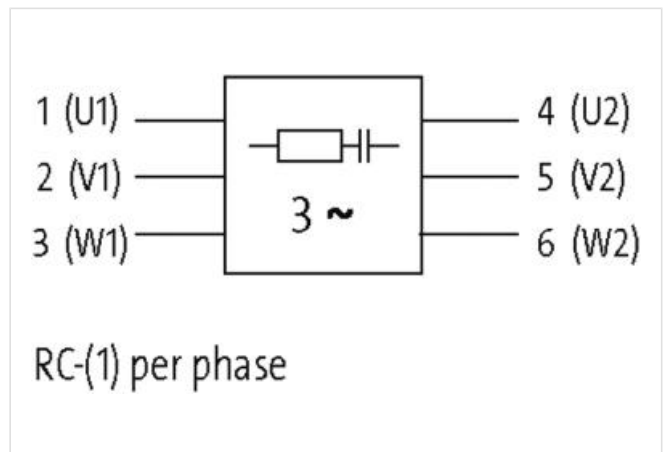
Model designation: RC 3 BUG/575-45

RC single

1 suppression module per phase required

For DIN-rail mounting use 2xArt.-No. 20900 adapter feet

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0

27371013

ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-8.0	27371013
ECLASS-9.0	27371013
ECLASS-10.1	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ETIM-5.0	EC000683
customs tariff number	85363010
customs tariff number	85363010
GTIN	4048879019354
GTIN	4048879019354
Packaging unit	1
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	575 V
Installation	
Connection cross section max.	1 mm ²
Installation Connection	
Connection information	Single strands
Length single strands	500 mm
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Height	92 mm
Width	61 mm
Depth	25 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C