

SV-SUB D 50 .-KL FOR SIGNAL TRANSFER

125 VAC/DC / 2 A

Art.No.: 54044

Weight: 0.222

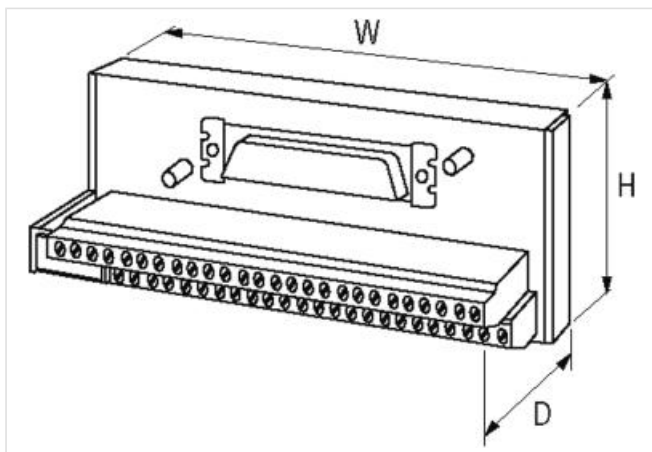
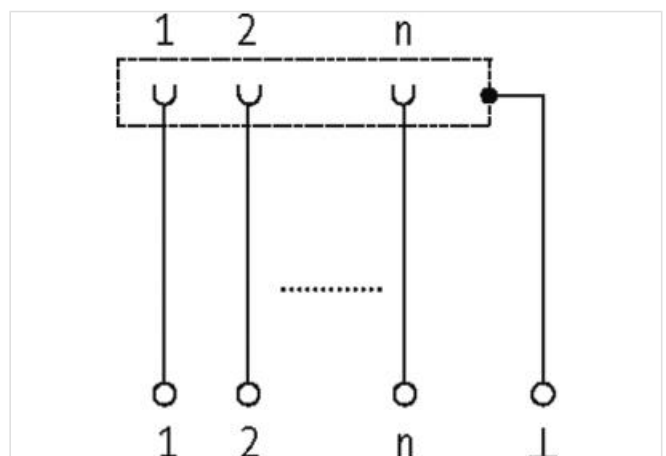
Country of origin: CZ

Model designation: SV-SUB D 50Bu.-KL

Female connector

50-pole

Screw terminals

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152

ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85366990
customs tariff number	85366990
GTIN	4048879026451
GTIN	4048879026451
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage AC	125 V
Operating voltage DC	150 V
Operating current max.	2 A

Device protection | Electrical

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	95 mm
Depth	58 mm
Looking techniques	Standard UNC 4-40 screw thread bolt (EN 60807)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C