




PKB 1 FOR SIGNAL TRANSFER

250V / 15 A
Art.No.: 54250
Weight: 0.286
Country of origin: CZ
Model designation: PKB 1

4x 22-pole
15 A per potential rail
Screw plug-in terminals

Link to Product

Illustration

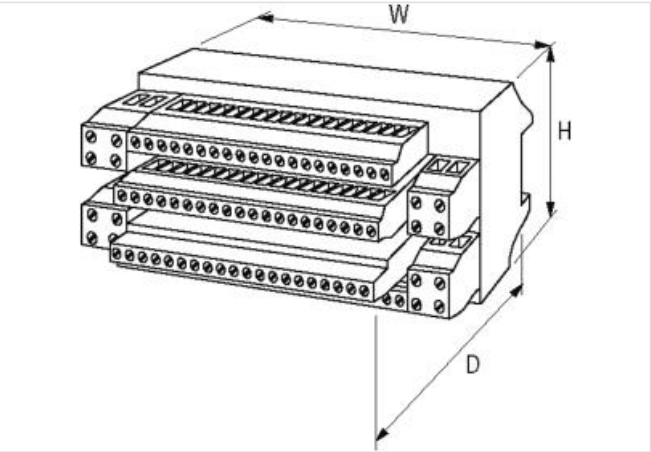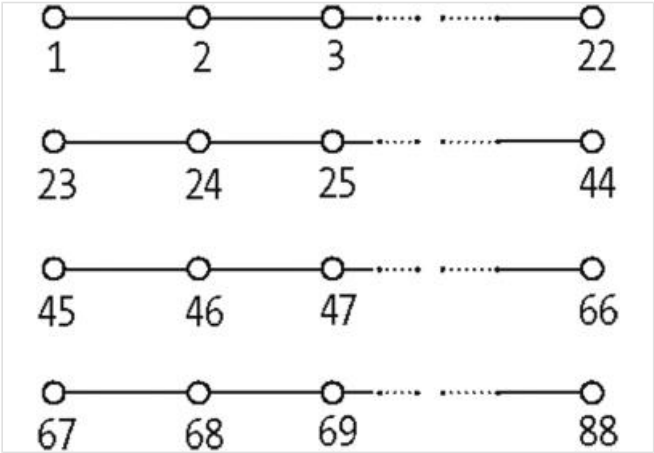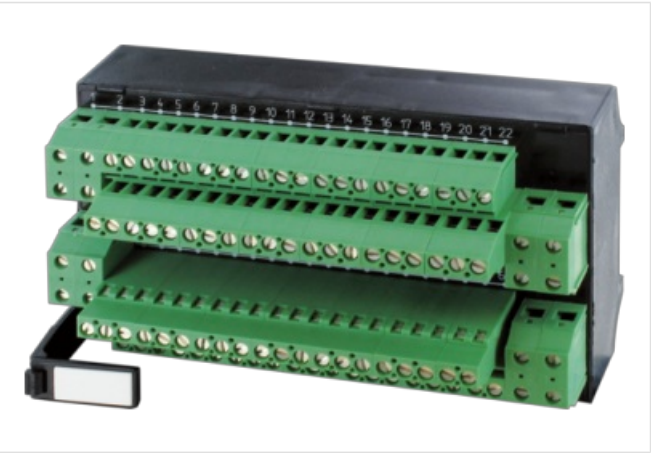

Product may differ from Image



Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152

ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
ETIM-6.0	EC001283
ETIM-7.0	EC001283
ETIM-8.0	EC001283
customs tariff number	85369010
customs tariff number	85369010
GTIN	4048879026062
GTIN	4048879026062
Packaging unit	1
Packaging unit	1

Electrical data | Supply

Operating voltage AC	250 V
Total current per potential rail max.	15 A

Installation

Connection cross-section solid max.	4 mm ²
-------------------------------------	-------------------

Installation | Connection

Connection	Screw terminals SK
------------	--------------------

Device protection | Electrical

Overvoltage category (EN 60664-1)	II
-----------------------------------	----

Mechanical data | Mounting data

Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	63 mm
Width	140 mm
Depth	48 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C