




MTS 1-Phase safety and isolating transformer

P: 160VA IN: 230VAC +/- 15VAC OUT: 24VAC

The MST series comprises single-phase safety transformers/isolating transformers of the protection class I and protection degree IP00 with double insulation between the primary and secondary windings for general use in industrial applications.

제품 링크

일러스트

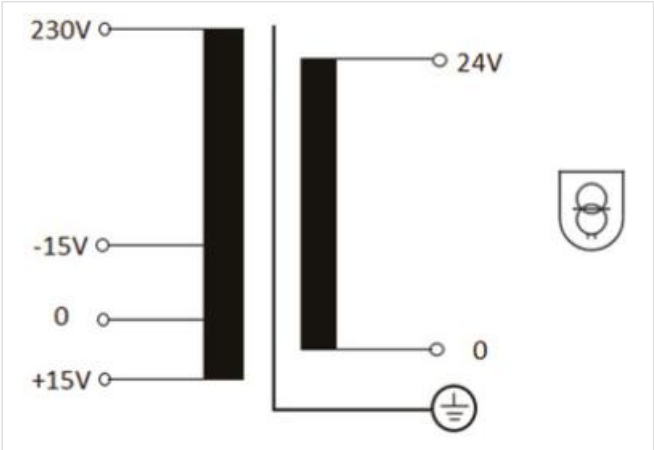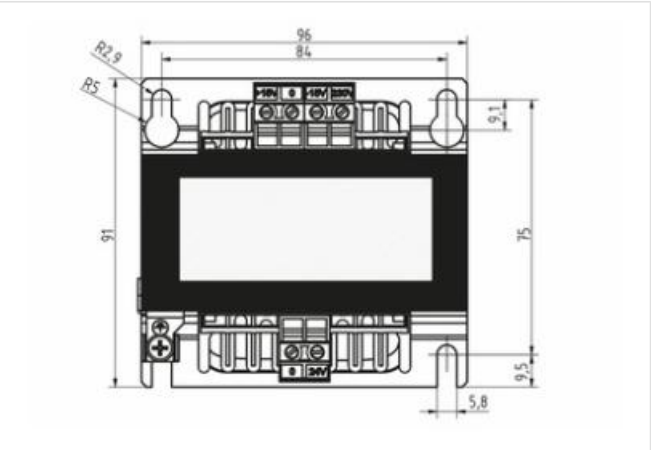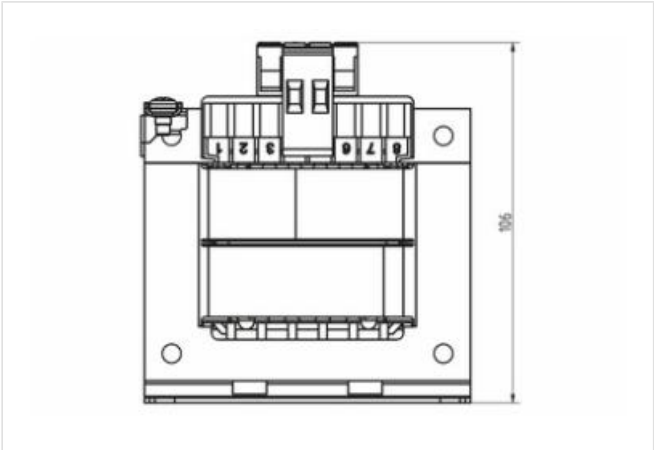

실제 제품은 이미지와 다를 수 있습니다.



Electrical data | Supply

Power frequency 50/60 Hz

Electrical data | Input

Input voltage AC	230 V
Current input AC	0,82 A
Max. inrush current	10,8 A
Short-circuit current	10 A

Electrical data | Output

Output voltage AC24 V

Mechanical data | Mounting data

Mounting methodscrewed
Suitable for mounting typeSchlüssellochauhängung
Mounting dimension a75 mm
Mounting dimension b84 mm
Mounting dimension c2,9 mm
Height91 mm
Width96 mm
Depth106 mm
Diameter bore2,9 mm
Length bore9,1 mm

Environmental characteristics | Climatic

Ambient temperature min.-20 °C
Ambient temperature max.40 °C
Storage temperature min.-30 °C
Storage temperature max.80 °C

Conformity

Product standardEN 61558-1, EN 61558-2-6, EN 62041
EMC2014/30/EU

제품자료

GTIN4065909078860
세번부호85043180
포장단위1