



MET 1-Phase safety and isolating transformer

P: 160VA IN: 230-400VAC +/- 15VAC OUT: 24VAC


The MET series comprises single-phase safety transformers/isolating transformers of the protection class I and protection degree IP00 with double insulation between the primary and secondary windings for general use in industrial applications.

Link to Product

Illustration

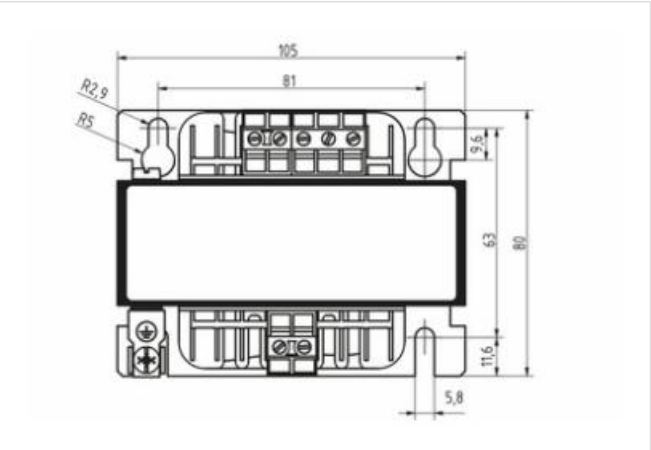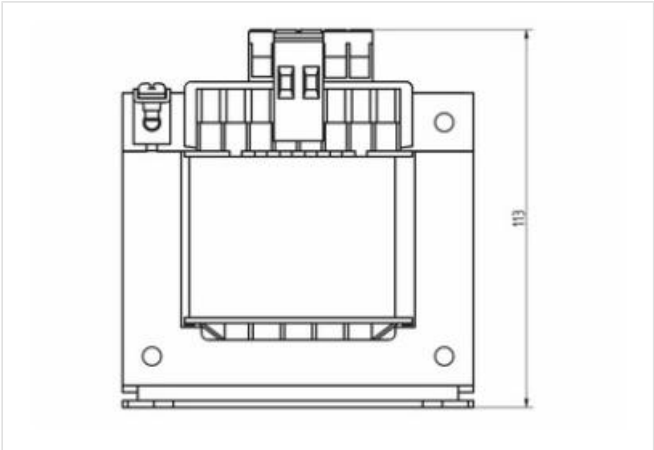

Product may differ from Image

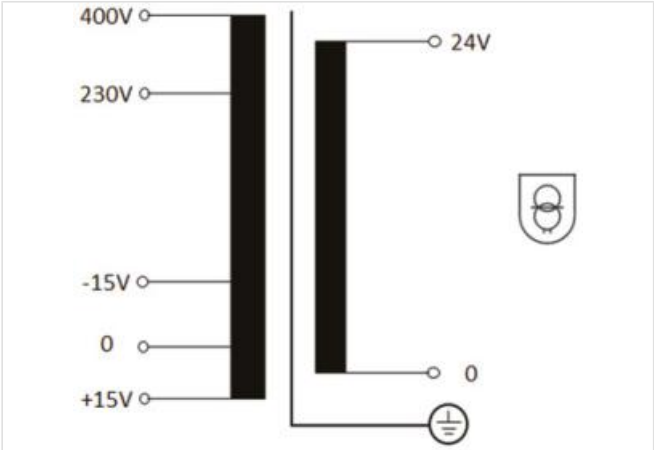

Electrical data | Supply

Power frequency 50/60 Hz

Electrical data | Input

Input voltage 1 AC	230 V
Input voltage 2 AC	400 V
Input current at input voltage 1 AC	0,79 A
Input current at input voltage 2 AC	0,45 A

Inrush current at input voltage 1	15,4 A
-----------------------------------	--------

Inrush current at input voltage 2	8,9 A
-----------------------------------	-------

Short-circuit current at input voltage 1	13,2 A
--	--------

Short-circuit current at input voltage 2	7,6 A
--	-------

Electrical data | Output

Output voltage AC	24 V
-------------------	------

Mechanical data | Mounting data

Mounting method	screwed
-----------------	---------

Suitable for mounting type	Schlüssellochaufhängung
----------------------------	-------------------------

Mounting dimension a	63 mm
----------------------	-------

Mounting dimension b	81 mm
----------------------	-------

Mounting dimension c	2,9 mm
----------------------	--------

Height	80 mm
--------	-------

Width	105 mm
-------	--------

Depth	113 mm
-------	--------

Diameter bore	2,9 mm
---------------	--------

Length bore	9,6 mm
-------------	--------

Environmental characteristics | Climatic

Ambient temperature min.	-20 °C
--------------------------	--------

Ambient temperature max.	50 °C
--------------------------	-------

Storage temperature min.	-30 °C
--------------------------	--------

Storage temperature max.	80 °C
--------------------------	-------

Conformity

Product standard	EN 61558-1, EN 61558-2-6, EN 62041
------------------	------------------------------------

EMC	2014/30/EU
-----	------------

取引条件

GTIN	4065909078662
------	---------------

HSコード	85043180
-------	----------

Packaging unit	1
----------------	---