





MET 1-Phase safety and isolating transformer

P: 250VA IN: 230-400VAC +/- 15VAC OUT: 24VAC

The MET series comprises single-phase safety transformers/isolating transformers of the protection class I and protection degree IP00 with double insulation between the primary and secondary windings for general use in industrial applications.

제품 링크

일러스트

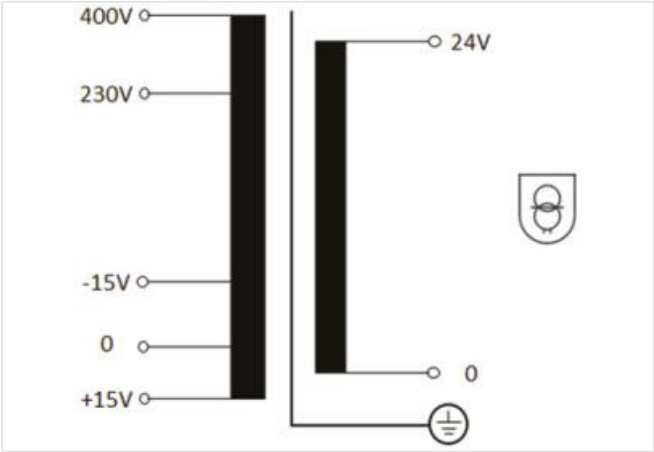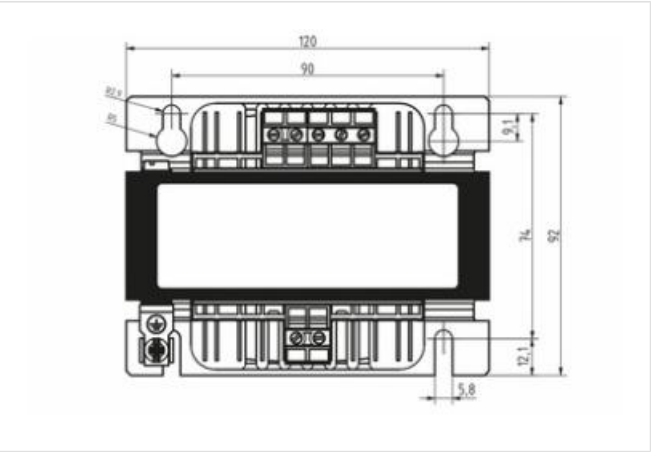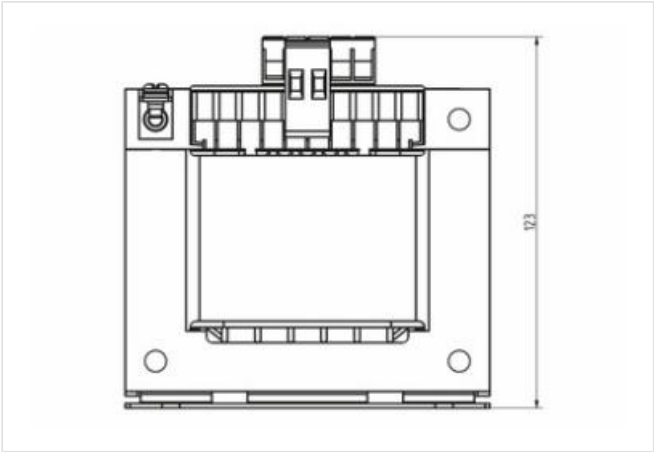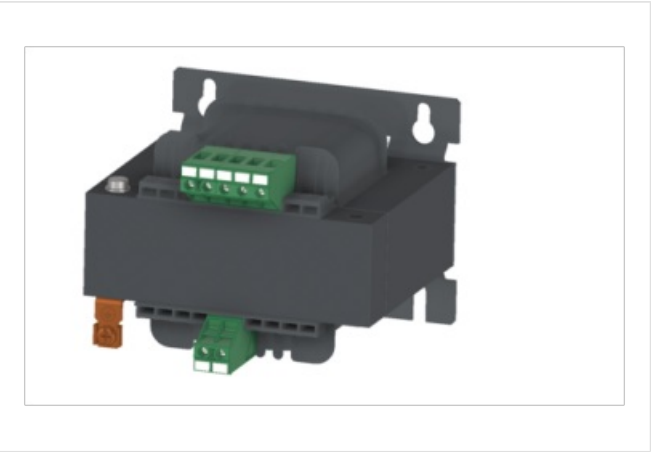

실제 제품은 이미지와 다를 수 있습니다.



Electrical data | Supply

Power frequency 50/60 Hz

Electrical data | Input

Input voltage 1 AC	230 V
Input voltage 2 AC	400 V
Input current at input voltage 1 AC	1,2 A
Input current at input voltage 2 AC	0,7 A

Inrush current at input voltage 1	23 A
Inrush current at input voltage 2	13,2 A
Short-circuit current at input voltage 1	23,8 A
Short-circuit current at input voltage 2	13,7 A

Electrical data | Output

Output voltage AC	24 V
-------------------	------

Mechanical data | Mounting data

Mounting method	screwed
Suitable for mounting type	Schlüssellochaufhängung
Mounting dimension a	74 mm
Mounting dimension b	90 mm
Mounting dimension c	2,9 mm
Height	92 mm
Width	120 mm
Depth	123 mm
Diameter bore	2,9 mm
Length bore	9,1 mm

Environmental characteristics | Climatic

Ambient temperature min.	-20 °C
Ambient temperature max.	50 °C
Storage temperature min.	-30 °C
Storage temperature max.	80 °C

Conformity

Product standard	EN 61558-1, EN 61558-2-6, EN 62041
EMC	2014/30/EU

제품자료

GTIN	4065909078679
세번부호	85043180
포장단위	1