


MDT three-phase control and isolation transformer

P:21000VA IN:3x400VAC±5% OUT:3x400VAC


3-phase isolation transformer
21 000 VA
Isolation class T 40/H
Other voltages on request.

Link to Product

Illustration

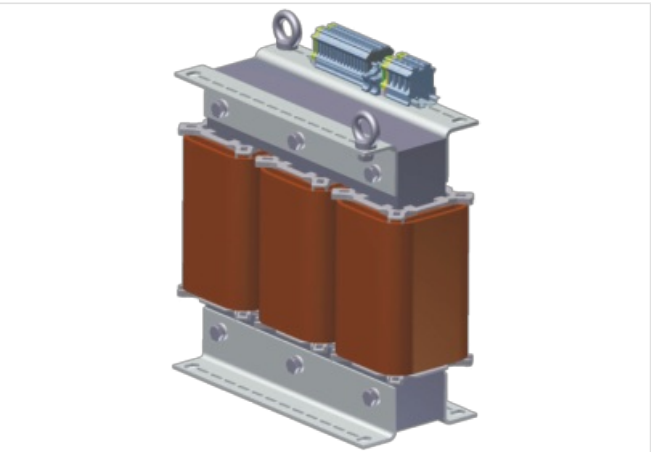

Product may differ from Image

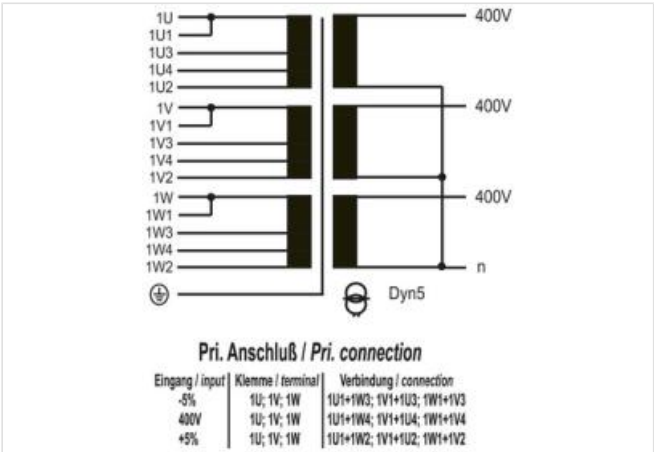

取引条件	
ECLASS-6.0	27031301
ECLASS-6.1	27031301
ECLASS-7.0	27031301
ECLASS-8.0	27031301
ECLASS-9.0	27031301
ECLASS-10.1	27031301
ECLASS-11.1	27031301
ECLASS-12.0	27031301
ETIM-5.0	EC002485
GTIN	4048879593366
HSコード	85043300
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	400 V
Input voltage AC min.	380 V
Input voltage AC max.	420 V
Input current AC (3-phase)	31,7 A
Max. inrush current	665,7 A

Short-circuit current	749 A
Phase number input	3
Electrical data Output	
Output voltage	3× 400 V AC
Output voltage AC	400 V
Output voltage adjustable	no
Power rating AC max.	21000 VA
Device protection Electrical	
Insulation test voltage input - output	4,5 kV
Mechanical data Mounting data	
Mounting method	screwed
Mounting dimension a	316 mm
Mounting dimension b	173 mm
Height	460 mm
Width	420 mm
Depth	260 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	40 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C