



MVP12, 6XM12, MOSA, PLUGGABLE CABLE

5.0m PUR-JB 12x0,34+5x0,75

6-way, 5-pole, MOSA
PUR/PVC (UL/CSA)
5.0 m
potentially separated
with LED for digital PNP-signals 24 V DC
quick connection elements included

Ürün Linki

örnekleme

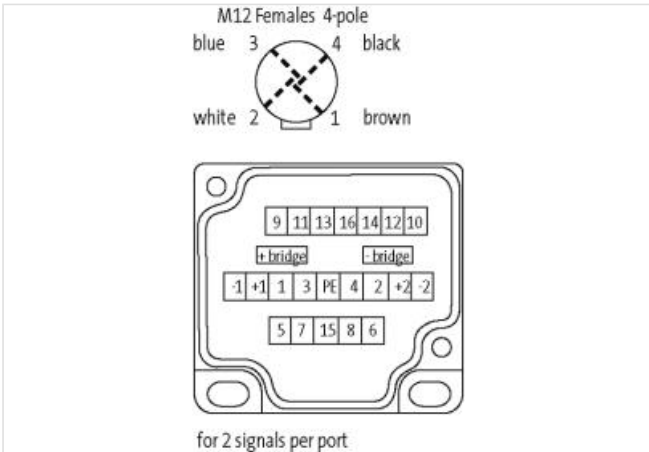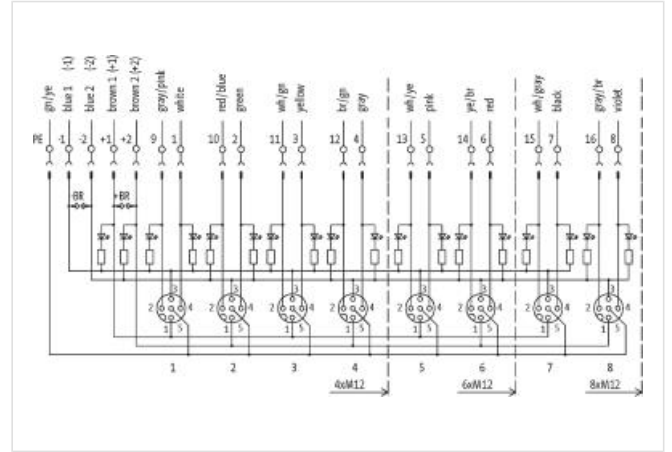

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-8.0	27279219
ECLASS-9.0	27440108
ECLASS-10.1	27440108
ECLASS-11.1	27440108
ECLASS-12.0	27440108

ETIM-5.0	EC002585
GTIN	4048879057608
Gümrük tarife no (gtip)	85369010
Paket miktarı	1
Electrical data Supply	
Operating voltage DC	24 V
Current operating per contact max.	4 A
Total current at 1 time current feed-in max.	8 A
Total current at 2 times current feed-in max.	16 A
Industrial communication	
Number of signals per port	2
Installation	
Connection cross section min.	0,25 mm ²
Connection cross section max.	0,5 mm ²
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP67
Additional condition protection degree	screwed, mounted
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Mechanical data Mounting data	
Mounting method	Cap nut
Height	43 mm
Width	50,2 mm
Depth	122 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	80 °C