


MODLINK MSDD DBL COMBI INSERT GERMANY

1xRJ45+USB-A + RCD opening

- 1× Germany (VDE) white
- 1× USB 3.0 (female/female) form A
- 1× RJ45, 8-pole metal, CAT5e (female/female)
- 1× FI cut-out

제품 링크

일러스트

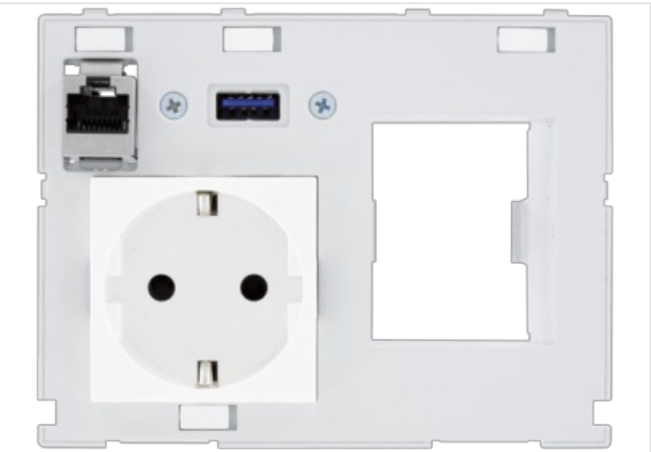

실제 제품은 이미지와 다를 수 있습니다.



제품자료	
ECLASS-6.0	27189217
ECLASS-6.1	27189217
ECLASS-7.0	27189217
ECLASS-8.0	27189217
ECLASS-9.0	27182806
ECLASS-10.1	27182806
ECLASS-11.1	27182806
ECLASS-12.0	27182806
ETIM-5.0	EC002625
GTIN	4048879401869
세번부호	85366990
포장단위	1
Mechanical data Mounting data	
Height	88 mm
Width	116 mm
Depth	70 mm
Environmental characteristics Climatic	
Storage temperature min.	5 °C
Storage temperature max.	40 °C
Germany (VDE)	

Connection cross section max.	2,5 mm²
AWG number max.	14
Operating voltage AC	250 V
Operating current	16 A
Connection	Spring clamp terminals FK
No. of poles	2 + PE
Connections per pole	2
Protection contact present	yes
USB	
Operating voltage AC	48 V
Operating voltage DC	48 V
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Operating current	1,5 A
USB specification	3.0
Data transmission rate max.	5000 MBit/s
Looking techniques	Snap-in connector
RJ45	
Operating voltage AC max. (UL-listed)	30 V
Operating voltage DC max. (UL-listed)	42,4 V
Current operating max. (UL)	175 mA
Family construction form	RJ45
Family type Back side	RJ45
Cable category min.	Cat5e
Looking techniques	Snap-in connector