


**Modlink MSDD-set: Frame 4000-68223-0000000,**  
insert 4000-68000-3250000 + 4000-68000-1210000

## 제품 링크

### 일러스트

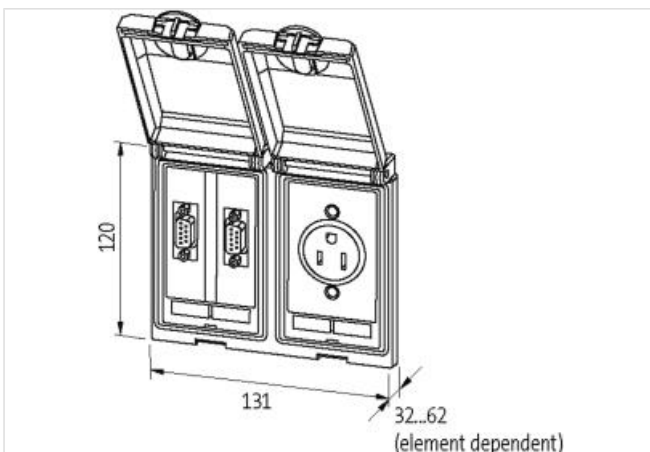

실제 제품은 이미지와 다를 수 있습니다.



| 제품자료        |               |
|-------------|---------------|
| ECLASS-6.0  | 27189217      |
| ECLASS-6.1  | 27189217      |
| ECLASS-7.0  | 27189217      |
| ECLASS-8.0  | 27189217      |
| ECLASS-9.0  | 27189217      |
| ECLASS-10.1 | 27182806      |
| ECLASS-11.1 | 27182806      |
| ECLASS-12.0 | 27182806      |
| ETIM-5.0    | EC002625      |
| GTIN        | 4048879330770 |
| 세번부호        | 85366990      |
| 포장단위        | 1             |

| Frame                                         |                       |
|-----------------------------------------------|-----------------------|
| Degree of protection (EN IEC 60529)           | IP65                  |
| Operating temperature min.                    | -10 °C                |
| Operating temperature max.                    | 60 °C                 |
| Storage temperature min.                      | -25 °C                |
| Storage temperature max.                      | 60 °C                 |
| Suitable for installation wall thickness min. | 1 mm                  |
| Suitable for installation wall thickness max. | 5 mm                  |
| Coating housing                               | surface finished      |
| Color cover                                   | transparent           |
| Material lid                                  | PC                    |
| Material housing                              | Fine zinc die casting |

| China (CCC)                                          |                    |
|------------------------------------------------------|--------------------|
| Connection cross-section solid max.                  | 4 mm²              |
| Connection cross-section stranded/fine-stranded max. | 4 mm²              |
| Operating voltage AC                                 | 250 V              |
| Operating current                                    | 10 A               |
| Connection                                           | Screw terminals SK |
| No. of poles                                         | 2 + PE             |
| Connections per pole                                 | 2                  |
| Protection contact present                           | yes                |

| RJ45                                  |                   |
|---------------------------------------|-------------------|
| Operating voltage AC max. (UL-listed) | 30 V              |
| Operating voltage DC max. (UL-listed) | 42,4 V            |
| Current operating max. (UL)           | 175 mA            |
| Family construction form              | RJ45              |
| Family type Back side                 | RJ45              |
| Cable category min.                   | Cat5e             |
| Looking techniques                    | Snap-in connector |