

SVS VALVE PLUG FORM B 10 MM FIELD-WIREABLE




0...230V M16x1.5

Form B (10 mm)
max. 230 V AC/DC
without components
metric

Plastic housings with good resistance against chemicals and oils.
The resistance to aggressive media should be individually tested for your application. Further details on request.

Link to Product

Illustration

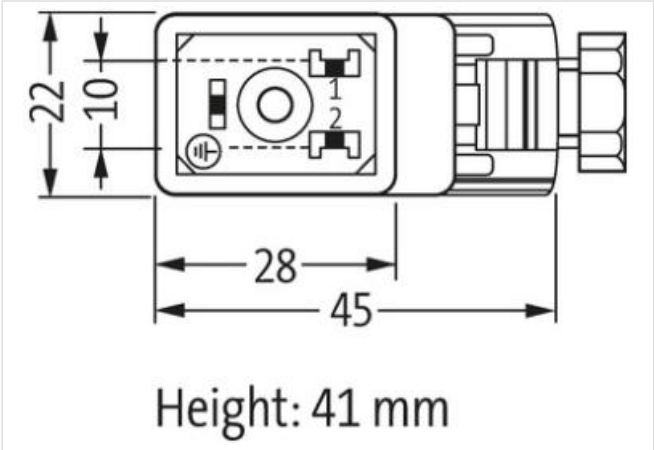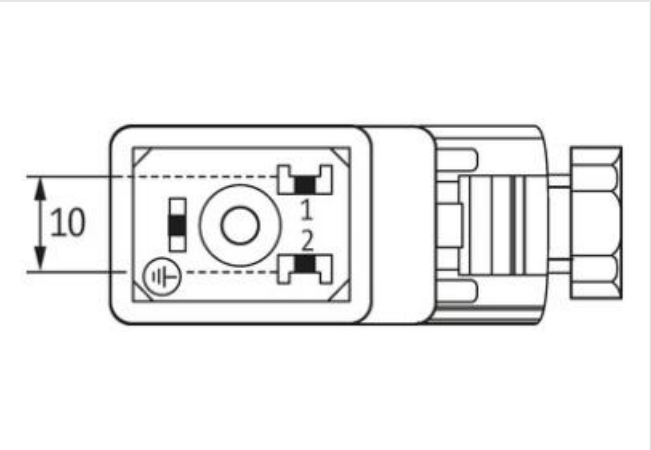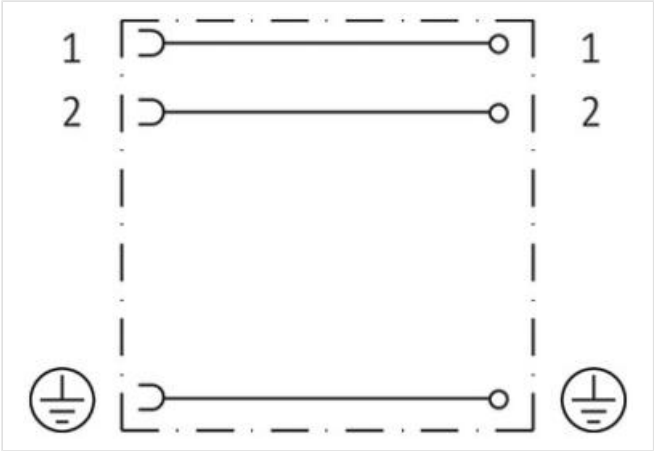

Product may differ from Image

Side 1	
Degree of protection (EN IEC 60529)	IP65
取引条件	
ECLASS-6.0	27279221
ECLASS-7.0	27440104
ECLASS-8.0	27440104
ECLASS-9.0	27440102
ETIM-5.0	EC002062
GTIN	4048879187220

HSコード	85366990
Packaging unit	1
Electrical data Supply	
Operating voltage AC max.	230 V
Operating voltage DC max.	230 V
Current operating per contact max.	10 A
Installation	
Connection cross section max.	1,5 mm²
Installation Connection	
Tightening torque	0,4 Nm
Mounting set	M16 x 1.5
Device protection Electrical	
Additional condition protection degree	inserted, locked, with screw connection
Mechanical data Mounting data	
fastening screw	M3
Clamping range min.	5 mm
Clamping range max.	10 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C