

B6 Surface mounted h., IP68

Screw locking, side entry M32

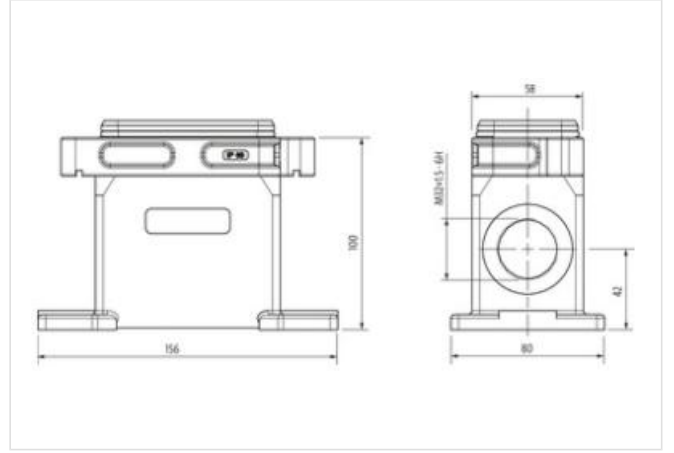
B6

Surface mounted housing

Screw locking

IP68

Technical data will be only guaranteed with Murrelektronik components.

Ürün Linki**örnekleme**

Ürün Image farklı olabilir

Ticari bilgiler

ECLASS-6.0	27143424
ECLASS-6.1	27261203
ECLASS-7.0	27440202
ECLASS-8.0	27440202
ECLASS-9.0	27440202
ECLASS-10.1	27440202
ECLASS-11.1	27440202
ECLASS-12.0	27440202
ETIM-5.0	EC000437
GTIN	4048879647335
Gümrük tarife no (gtip)	85389099
Paket miktarı	1

Installation

Cable outlet laterally

Installation | Connection

Mounting set	M32
Mating cycles min.	500

Device protection | Electrical

Degree of protection (EN IEC 60529)	IP68
Additional condition protection degree	inserted, locked, with screw connection

Mechanical data

Housing type Surface mounted housing

Mechanical data | Material data

Coating housing	powder-coated
-----------------	---------------

Material gasket	Silicon
-----------------	---------

Material housing	Aluminum die casting
------------------	----------------------

Locking material	Stainless steel
------------------	-----------------

Mechanical data | Mounting data

Size	B6
------	----

Mounting method	Screw locking
-----------------	---------------

Height	100 mm
--------	--------

Width	80 mm
-------	-------

Depth	156 mm
-------	--------

Environmental characteristics | Climatic

Operating temperature min.	-40 °C
----------------------------	--------

Operating temperature max.	125 °C
----------------------------	--------

Climatic category (EN IEC 60068-1)	40/125/21
------------------------------------	-----------