

ALLEN-BRADLEY CONTACTOR SUPPRESSOR

RC, 240VAC/DC


230 V AC/DC

RC

For other configurations and voltages, please inquire.

Link to Product

Illustration

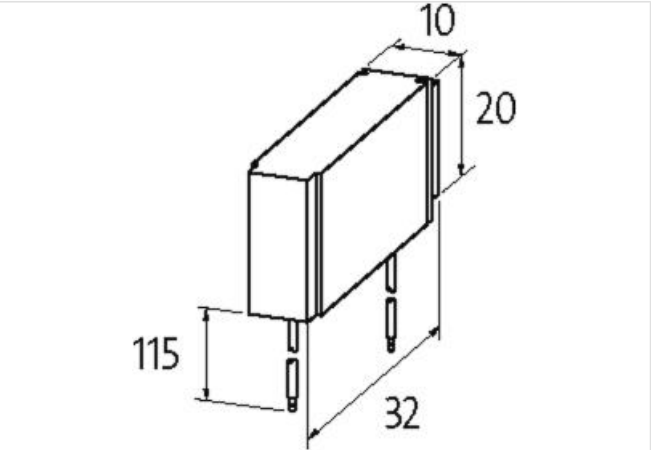

Product may differ from Image



| Commercial data                 |               |
|---------------------------------|---------------|
| ECLASS-6.0                      | 27371013      |
| customs tariff number           | 85363010      |
| GTIN                            | 4048879020060 |
| Packaging unit                  | 1             |
| Compatibility   Compatible with |               |
| Appropriate contactors          | 100-M         |
| Electrical data                 |               |

|                |         |
|----------------|---------|
| Damping factor | 1.5× UN |
|----------------|---------|

**Electrical data | Input**

|                       |       |
|-----------------------|-------|
| Input voltage AC min. | 110 V |
|-----------------------|-------|

|                       |       |
|-----------------------|-------|
| Input voltage AC max. | 250 V |
|-----------------------|-------|

|                       |       |
|-----------------------|-------|
| Input voltage DC min. | 110 V |
|-----------------------|-------|

|                       |       |
|-----------------------|-------|
| Input voltage DC max. | 250 V |
|-----------------------|-------|

**Installation | Connection**

|                        |                           |
|------------------------|---------------------------|
| Connection information | flexible connection wires |
|------------------------|---------------------------|

**Device protection | Media**

|                  |                 |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

**Mechanical data | Material data**

|                                     |     |
|-------------------------------------|-----|
| Combustibility class housing (UL94) | V-0 |
|-------------------------------------|-----|

|                  |         |
|------------------|---------|
| Material housing | Plastic |
|------------------|---------|

**Mechanical data | Mounting data**

|        |       |
|--------|-------|
| Height | 20 mm |
|--------|-------|

|       |       |
|-------|-------|
| Width | 10 mm |
|-------|-------|

|       |       |
|-------|-------|
| Depth | 32 mm |
|-------|-------|

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
|----------------------------|--------|

|                            |       |
|----------------------------|-------|
| Operating temperature max. | 70 °C |
|----------------------------|-------|