

SIEMENS CONTACTOR SUPPRESSOR

RC, 230VAC/DC


230 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

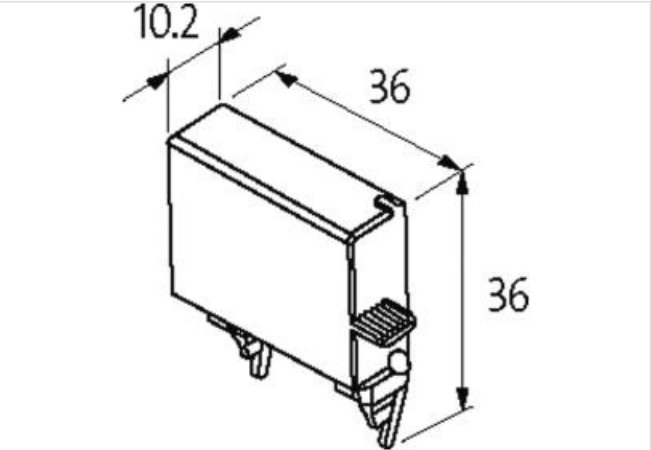

Product may differ from Image



| Commercial data |          |
|-----------------|----------|
| ECLASS-6.0      | 27371013 |
| ECLASS-6.1      | 27371013 |
| ECLASS-7.0      | 27371013 |
| ECLASS-8.0      | 27371013 |
| ECLASS-9.0      | 27371013 |
| ECLASS-10.1     | 27371013 |

|                       |               |
|-----------------------|---------------|
| ECLASS-11.1           | 27371013      |
| ECLASS-12.0           | 27371013      |
| ETIM-5.0              | EC002498      |
| customs tariff number | 85363010      |
| GTIN                  | 4048879019941 |
| Packaging unit        | 1             |

**Compatibility | Compatible with**

|                        |                  |
|------------------------|------------------|
| Appropriate contactors | 3 RT 10.24/25/26 |
|------------------------|------------------|

**Electrical data | Input**

|                       |       |
|-----------------------|-------|
| Input voltage AC min. | 127 V |
| Input voltage AC max. | 250 V |
| Input voltage DC min. | 127 V |
| Input voltage DC max. | 250 V |

**Mechanical data | Mounting data**

|        |         |
|--------|---------|
| Height | 36 mm   |
| Width  | 36 mm   |
| Depth  | 10,2 mm |

**Environmental characteristics | Climatic**

|                            |        |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C  |