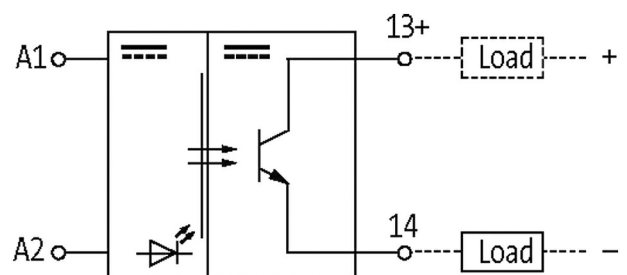
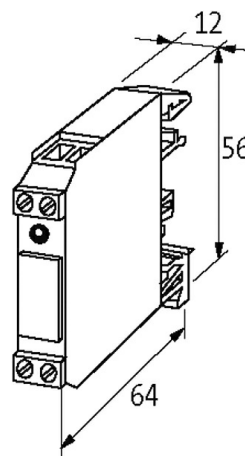


AMMS 18-1 OPTO-COUPLER MODULE

IN: 30 VDC - OUT: 30 VDC / 1,2 A

Transistor 2 A

24 V DC

[Link to Product](#)**Illustration**

Product may differ from Image

General data

Test isolation voltage	2.5 kV
Housing	Black plastic, flame retardant
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)

The information in this brochure has been compiled with the utmost care.
 Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21

Temperature range -20...+60 °C

Output

Switching voltage 6...30 V DC

Output current max. 1.2 A

Switching time ON/OFF 1.5 µs/1 ms

Switching frequency max. 20 kHz

Switching current per output 1 mA...1.2 A

Input

Voltage range ON 6...30 V DC

Input current 8.5 mA (24 V DC)

LED display LED (red)

Commercial data

country of origin CZ

customs tariff number 85414090

EAN 4048879027885

eClass 27371604

Packaging unit 1