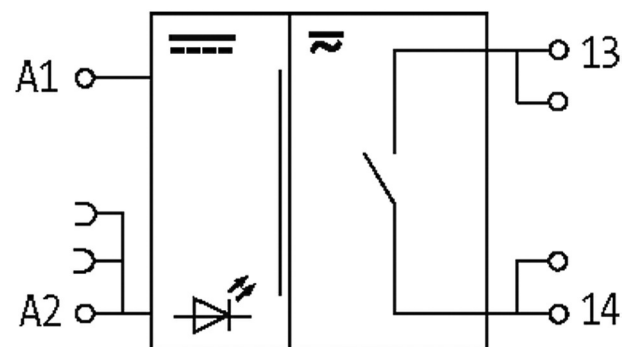
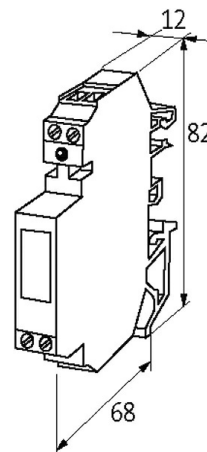


RMMDA 11/230 OUTPUT RELAY

IN: 230 VAC/DC - OUT: 250 VAC/DC / 6 A

1 relay; 1 NO contact
6 A
230 V AC/DC
with minus plug link

[Link to Product](#)**Illustration**

Product may differ from Image

General data

The information in this brochure has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 04/21

Test isolation voltage	4.0 kV
Dimensions H×W×D	82×12×68 mm
Mech./ elect. life	20 000 000 switching cycles/load dependent
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-20...+50 °C
Output	
Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	100 mA
Power rating (voltage dependent)	max. 2000 VA/240 W
Switching frequency	max. 10 Hz
Contact material	Ag Ni
Energize/release/contact bounce time	10/15/2 ms
Input	
Connection voltage - current	230 V AC/DC (195...253 V AC/DC) - 4.5 mA without plug link
LED display	LED (red)
Utilization category	
AC-15	4 A (24/110/230 V AC)
AC-1	6 A (24/110/230 V AC)
DC-13	2 A (24 V DC); 0.25 A (110 V DC); 0.1 A (230 V DC)
Commercial data	
country of origin	CZ
customs tariff number	85364900
EAN	4048879027786
eClass	27371001
Packaging unit	1