



## **RM 131/24 OUTPUT RELAY**

IN: 24 VDC - OUT: 250 VAC/DC / 5 A

1 relay; 3 NO contacts/1 NC contact  
5 A  
24 V DC  
with force guided contacts  
Screw terminals

[Link to Product](#)

**Illustration**

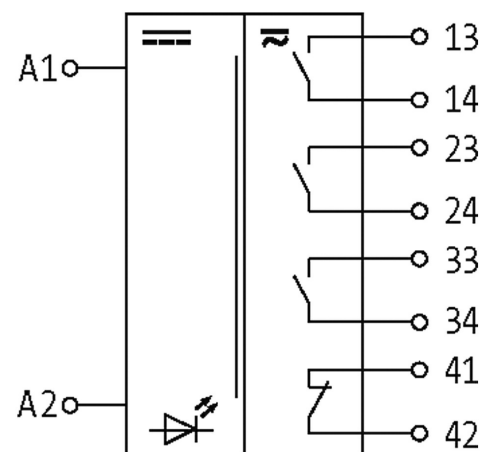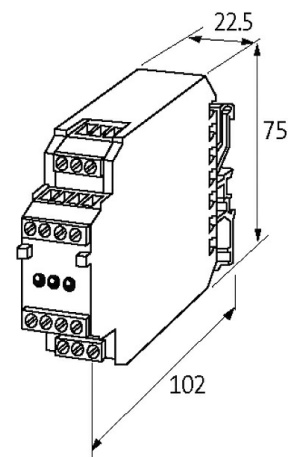

Product may differ from Image

#### General data

|                        |   |
|------------------------|---|
| Mech./ elect. life     | 1 000 000 switching cycles/load dependent |
| Test isolation voltage | 2.5 kV                                    |
| Mounting method        | DIN-rail mountable TH35 or G32 (EN 60715) |
| Temperature range      | -20...+50 °C                              |
| Dimensions HxWxD       | 75x22.5x102 mm                            |

#### Output

|                   |                  |
|-------------------|------------------|
| Switching voltage | max. 250 V AC/DC |
|-------------------|------------------|

The information in this brochure has been compiled with the utmost care.  
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 05/21

|                                      |                   |
|--------------------------------------|-------------------|
| Switching current per output         | max. 5 A          |
| Min. load current                    | 300 mA            |
| Power rating (voltage dependent)     | max. 1000 VA/50 W |
| Switching frequency                  | max. 1 Hz         |
| Contact material                     | Ag hv; Ag Sn O2   |
| Energize/release/contact bounce time | 15/15/2 ms        |

**Input**

|                              |                                  |
|------------------------------|----------------------------------|
| Connection voltage - current | 24 V DC (21.6...28 V DC) - 30 mA |
| LED display                  | LED (red)                        |

**Utilization category**

|       |   |
|-------|---|
| AC-1  | 5 A (24/110/230 V AC)                             |
| AC-15 | 4 A (24 V AC); 3 A (110 V AC); 2 A (230 V AC)     |
| DC-13 | 2 A (24 V DC); 0.4 A (110 V DC); 0.2 A (230 V DC) |

**Commercial data**

|                       |               |
|-----------------------|---------------|
| country of origin     | CZ            |
| customs tariff number | 85364900      |
| EAN                   | 4048879027687 |
| eClass                | 27371001      |
| Packaging unit        | 1             |