

RM-21/230V AC OUTPUT RELAY

IN: 230 VAC/DC - OUT: 250 VAC/DC / 5 A

2 relays; each 1 NO/NC contact



8 A

230 V AC

Screw terminals

[Link to Product](#)

Illustration

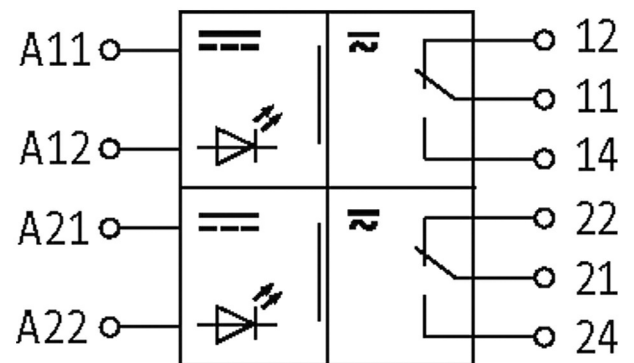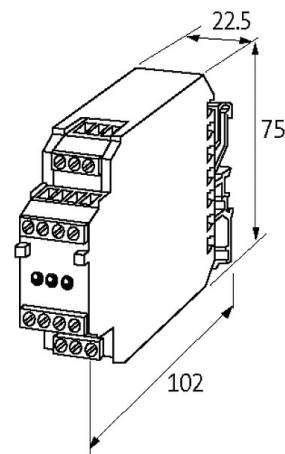

Product may differ from Image

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
Test isolation voltage	4.0 kV
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-20...+50 °C
Dimensions H×W×D	75×22.5×102 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 8 A
Min. load current	100 mA

The information in this brochure has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 02/21

Murrelektronik GmbH | Falkenstraße 3 | 71570 Oppenweiler | Fon +49 (71 91) 47-0 | Fax +49 (71 91) 47-491000 | shop@murrelektronik.com | shop.murrelektronik.com

Power rating (voltage dependent)	max. 1250 VA/240 W
Switching frequency	max. 0.1 Hz (with load)
Contact material	Ag Sn O ₂
Energize/release/contact bounce time	10/10/2 ms
Input	
Connection voltage - current	230 V AC (195...250 V AC) - 10 mA
LED display	LED (red)
Utilization category	
AC-1	8 A (24/110/230 V AC)
AC-15	3 A (24/110/230 V AC)
DC-13	1.5 A (24 V DC); 0.3 A (110 V DC); 0.15 A (230 V DC)
Commercial data	
country of origin	CZ
customs tariff number	85364900
EAN	4048879027632
eClass	27371001
Packaging unit	1