

RMM 11/230 V OUTPUT RELAY

IN: 230 VAC/DC - OUT: 250 VAC/DC / 6 A

1 relay; 1 NO contact



6 A

230 V AC

Screw terminals

[Link to Product](#)

Illustration

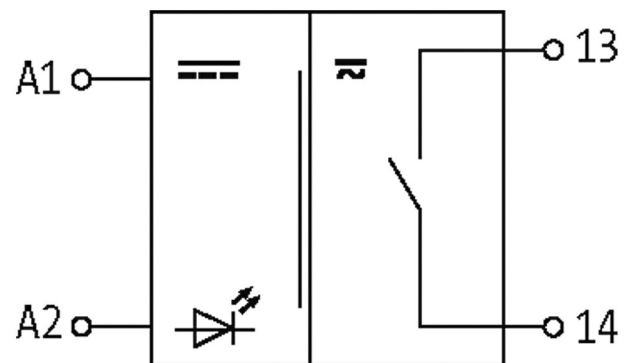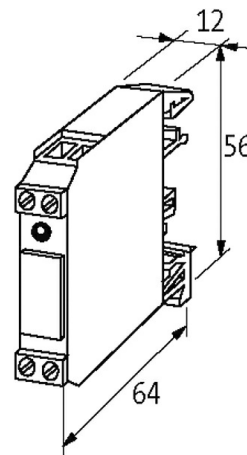

Product may differ from Image

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
Test isolation voltage	4.0 kV
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-20...+60 °C
Dimensions H×W×D	56×12×65 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 6 A
Min. load current	100 mA

The information in this brochure has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 03/21

Power rating (voltage dependent)	max. 1250 VA/240 W
Switching frequency	max. 10 Hz
Contact material	Ag Ni 0.15 hv; Ag hv
Energize/release/contact bounce time	10/15/1.5 ms

Input

Connection voltage - current	230 V AC/DC (195...250 V AC/DC) - 3.5 mA
LED display	LED (red)

Utilization category

AC-12	6 A (24/110/230 V AC)
AC-15	4 A (24/110/230 V AC)
DC-13	2 A (24 V DC); 0.25 A (110 V DC); 0.1 A (230 V DC)

Commercial data

country of origin	CZ
customs tariff number	85364900
EAN	4048879027557
eClass	27371001
Packaging unit	1