

RMMR11/24VDC WITH GROUND BRIDGE OUTPUT RELAY

IN: 24 VAC/DC - OUT: 250 VAC/DC / 5 A

1 relay; 1 NC contact

5 A



24 V AC/DC

with minus plug link

Screw terminals

[Link to Product](#)

Illustration

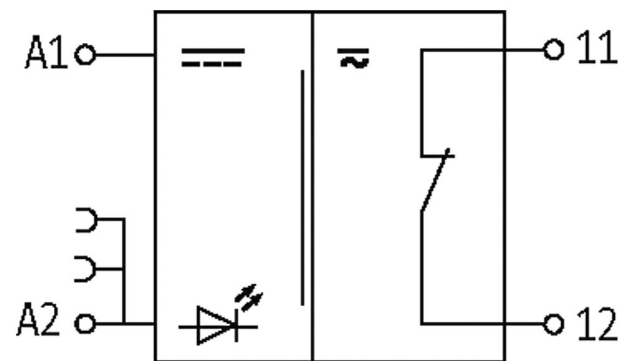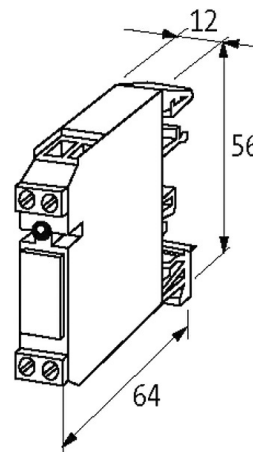

Product may differ from Image

General data

Mech./ elect. life	20 000 000 switching cycles/load dependent
Test isolation voltage	4.0 kV
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-25...+60 °C (storage temperature -40...+80 °C)
Dimensions H×W×D	56×12×65 mm

Output

Switching voltage	max. 250 V AC/DC
Switching current per output	max. 5 A

Min. load current	100 mA
Power rating (voltage dependent)	max. 1250 VA/240 W
Switching frequency	max. 10 Hz
Contact material	Ag Ni 0.15 hv
Energize/release/contact bounce time	10/15/1.5 ms

Input

Connection voltage - current	24 V AC/DC (19.2...30 V AC/DC) - 15 mA
Plug link (supplied)	Art-No. 90960
LED display	LED (red)

Utilization category

AC-1	5 A (24/110/230 V AC)
AC-15	3 A (24/110/230 V AC)
DC-13	1.3 A (24 V DC); 0.3 A (110 V DC); 0.15 A (230 V DC)

Commercial data

country of origin	CZ
customs tariff number	85364900
EAN	4048879027366
eClass	27371001
Packaging unit	1