



LUG S 8 FOR SIGNAL TRANSFER

250V / 8 A

8-pole
Screw plug-in terminals

[Link to Product](#)

Illustration

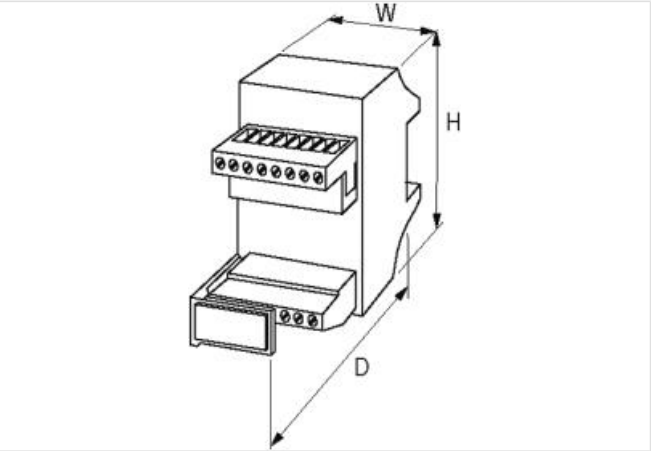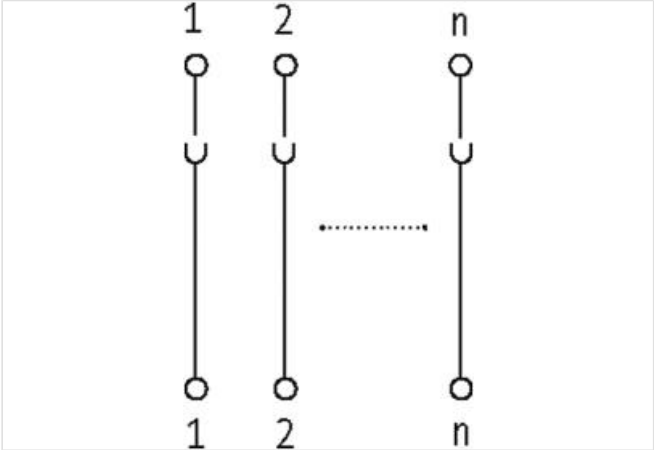

Product may differ from Image

Commercial data	
ECLASS-6.0	27143424
ECLASS-6.1	27260708
ECLASS-7.0	27141152
ECLASS-8.0	27141152
ECLASS-9.0	27141152
ECLASS-10.1	27141152
ECLASS-11.1	27141152
ECLASS-12.0	27141152
ETIM-5.0	EC001283
customs tariff number	85369010
GTIN	4048879026291
Packaging unit	1

Electrical data Supply	
Operating voltage AC	250 V
Operating current max.	8 A
Installation	
Connection cross-section solid max.	4 mm ²
Installation Connection	
Connection	Screw terminals SK
Mechanical data Mounting data	
Mounting method	geschnappt
Suitable for mounting type	mounting rail, (EN 60715)
Height	75 mm
Width	45 mm
Depth	66 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C