

PROFIBUS-PLUG-MALE (SUB-D) 90° WITH PG

Cut clamp for rigid and flexible wires


Bus connection plug 90°

PROFIBUS

SUB-D9 (male), IDC terminals, rigid and flexible cable, programming device connection

[Link to Product](#)

Illustration

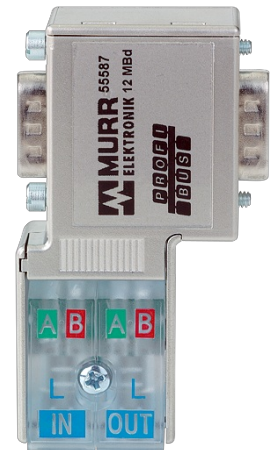

Product may differ from Image

Approvals



More Info



General data

Protection	IP20
Connection	PROFIBUS, FC cable rigid/flexible, 1 × 2 × 0.64 mm ² , for outer diameter 8.0 ± 0.5 mm
Dimensions H×W×D	72×40×17 mm
Pollution Degree	2
Temperature range	-25...+60 °C (storage temperature -25...+80 °C)

Technical Data

Operating voltage	4.75...5.25 V DC (via the fieldbus device)
Terminating resistor	integrated, switchable
Current consumption	max. 12.5 mA
Transfer rate	max. 12 Mbit/s

Commercial data

country of origin	DE
customs tariff number	85389091
EAN	4048879050555

eClass	27279221
Packaging unit	1
