

MASI20 INSTALLATION TECHNOL.

Plug terminal for AS-Interface profile cable


Plug terminal
for bus or power distributor

[Link to Product](#)

Illustration



Product may differ from Image

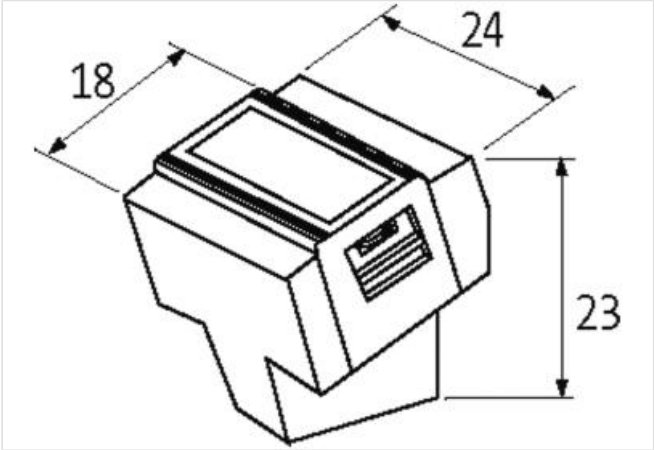

Commercial data	
ECLASS-6.0	27141106
ECLASS-6.1	27141104
ECLASS-7.0	27141104
ECLASS-8.0	27141104
ECLASS-9.0	27141104
ECLASS-10.1	27141104
ECLASS-11.1	27141104
ECLASS-12.0	27141104
ETIM-5.0	EC001583
customs tariff number	85369010
GTIN	4048879050517
Packaging unit	1
Electrical data Supply	
Operating voltage DC max.	36 V
Total current max.	8 A
Mechanical data Mounting data	
Height	23 mm
Width	24 mm
Depth	18 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C
Storage temperature min.	-40 °C
Storage temperature max.	80 °C
Connection type 1	
Connection	Screw terminals SK

Family construction form	terminal
Gender	female
Color contact carrier	green
No. of poles	2
PIN 1	+
PIN 2	-