

## POTENTIAL TERMINAL BLOCK GRAY

Potential terminal block  
gray/gray/gray/gray


### [Link to Product](#)

#### Illustration



Product may differ from Image

#### Approvals

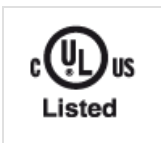

#### General data

Protection	IP20
Dimensions HxWxD	70x56x32.5 mm
Connection	Spring clamp terminals: 0.08...2.5 mm <sup>2</sup> (AWG 28...14)
Temperature range	0...+55 °C (storage temperature -40...+85 °C)

#### Technical Data

Operating voltage	max. 30 V AC/DC
Total current	max. 10 A

#### Commercial data

country of origin	DE
customs tariff number	85369010
EAN	4048879286893
eClass	27141106
Packaging unit	1