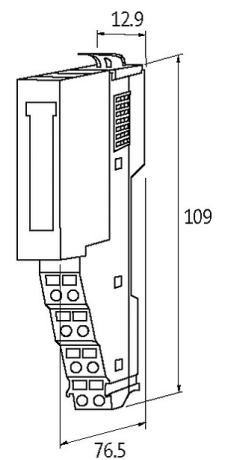


CUBE20S DIGITAL OUTPUT MODULE DO4

4x24VDC 0,5A

Expansion module
Digital outputs
DO4 - (E)

[Link to Product](#)**Illustration**

Product may differ from Image

Approvals**General data**

Protection	IP20
Connection	Spring clamp plug-in terminals: max. 1.5 mm ² (AWG 16)
Mounting method	DIN-rail mountable (EN 60715)
Temperature range	0...+60 °C (storage temperature -25...+70 °C)
Dimensions HxWxD	109x12.9x76.5 mm

Output

The information in this brochure has been compiled with the utmost care.
Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 04/21

Actuator supply UA	24 V DC (EN 61131-2), max. 2 A
Switching current per output	max. 0.5 A (short-circuit and overload protected)
Galvanic isolation	500 V DC between outputs and internal communication
Lamp load	5 W
Output delay time	175 ns

Internal communication

Module supply	via system connection
Current consumption	max. 55 mA

Diagnostic

Communication status	via LED
Diagnostic via LED	per module and channel
Diagnostic via BUS	per module
Monitoring - under voltage	yes
Monitoring - no voltage	no
Short-circuit and overload	yes

Commercial data

country of origin	TH
customs tariff number	85389099
EAN	4048879424479
eClass	27242604
Packaging unit	1