



PROFINET Managed Switch 10x10/100/1000BT IP67 Metal M12

[Link to Product](#)


Illustration

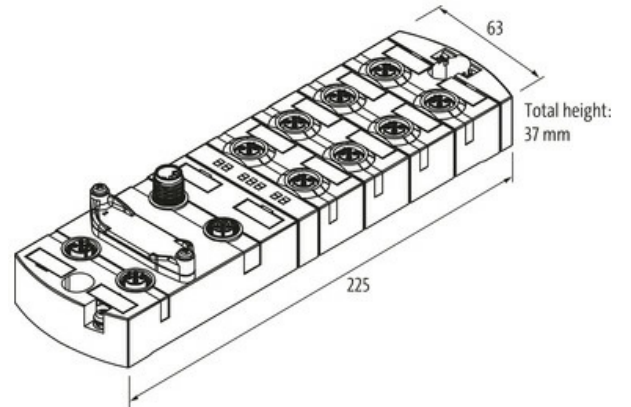


Female

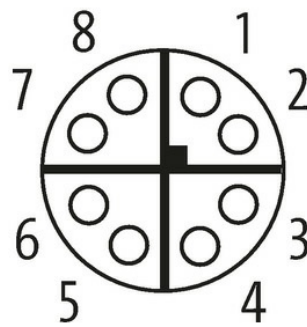

Male

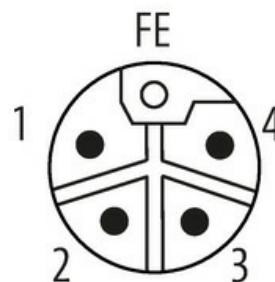

Female

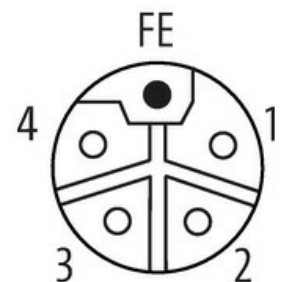

Product may differ from Image

Approvals

Approvals

More Info



Technical Data

Operating voltage	9...36 V
Transfer rate	10/100/1000 Mbit/s full duplex
Operating modes	Autocrossing Autonegotiation

General data

Mounting method	2-hole screw mounting
Temperature range	-25...+70 °C, ...+70 °C derating (storage temperature -40...+85 °C)
Housing	Metal
Protection	IP67
Dimensions HxWxD	37x63x225 mm

Connections

Fieldbus	10x M12 (female), D-coded
Supply	2x M12 Power, 5-pole, L-coded, 2x max. 16 A

PROFINET

Specification	V2.4, Conformance Class B
Addressing	DCP
FSU (Fast-Start-Up)	no
PROFINET Netload Class	III
MRP	yes
Shared Device/Input	no

Switch Management

Protocols	DHCP, SNMP (v1, v2c, v3), RSTP, STP, LLDP, NTP, RMON, SSH (CLI) Syslog
NAT	yes
Port Mirroring	yes
VLAN (QoS) IEEE 802.p	yes
Alarm contact	no
Remote maintenance	Open VPN
Websserver	HTTP, HTTPS
Switch Form	PROFINET - Managed Switch

Diagnostic

Communication status	via LED, LLDP
Monitoring - no voltage	yes

Commercial data

country of origin	DE
customs tariff number	85176200
EAN	4048879862592
Packaging unit	1.000